

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

19164-0068

Status:


Active

Overview:

Perma-Seal™ Terminals

Description:

Perma-Seal™ Ring Tongue Terminal for 10-12 AWG Wire, Stud Size 3/8" (M9)

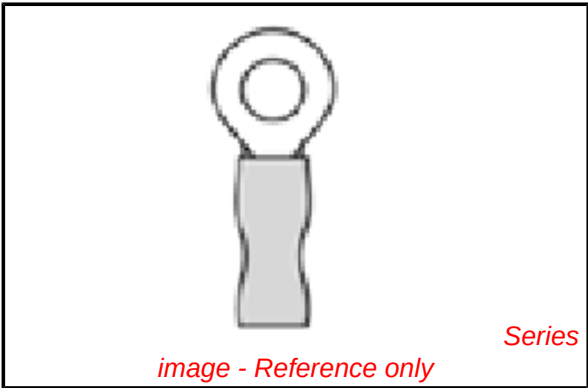

Documents:	
Drawing (PDF)	Product Specification PS-19902-013 (PDF)
Product Specification PS-19902-011 (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR18689
UL	E32244
General	
Product Family	Ring and Spade Terminals
Series	19164
Crimp Quality Equipment	Yes
Mil-Spec	N/A
MolexKits	Yes
Overview	Perma-Seal™ Terminals
Product Name	Perma-Seal™
Type	Ring
UPC	800753113527
Physical	
Barrel Type	Closed
Insulation	NiAc™
Material - Plating Mating	Tin
Net Weight	2.449/g
Packaging Type	Bag
Stud Size	3/8" (M9)
Wire Insulation Diameter	7.87mm
Wire Size AWG	10, 12
Wire Size mm²	3.09 - 5.01
Material Info	
Old Part Number	SC-240-38
Reference - Drawing Numbers	
Product Specification	PS-19902-011, PS-19902-013
Sales Drawing	SD-19164-041

EU RoHS

ELV and RoHS

Compliant

REACH SVHC

Not Reviewed

Low-Halogen Status

Low-Halogen

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com

For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

19164Series

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description	Product #
PremiumGrade™	0640017400
Hand Crimp Tool	
Power Crimp Tool	0640057400
Head for Terminals	
10-22 AWG Wire	

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION