

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [50-57-9506](#)
Status: **Active**
Overview: [SL™ Modular Connectors](#)
Description: [SL™ Crimp Housing, Single Row, Version H, Polarized Friction Lock, 6 Circuits](#)

Documents:

3D Model	Product Specification PS-71851 (PDF)
Drawing (PDF)	Test Summary TS-70058-001 (PDF)
Product Specification PS-70058 (PDF)	RoHS Certificate of Compliance (PDF)
Product Specification PS-70400 (PDF)	

Agency Certification

CSA	LR19980
UL	E29179

General

Product Family	Crimp Housings
Series	70066
Application	Signal, Wire-to-Board
Comments	Version H
Overview	SL™ Modular Connectors
Product Name	SL™
UPC	800754381345

Physical

Circuits (maximum)	6
Color - Resin	Black
Flammability	94V-0
Gender	Female
Glow-Wire Compliant	No
Keying to Mating Part	None
Lock to Mating Part	Yes
Material - Resin	Polyester Alloy
Net Weight	0.556/g
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.54mm
Stackable	Yes
Temperature Range - Operating	-40°C to +105°C

Electrical


Current - Maximum per Contact	3A
-------------------------------	----

Material Info

Old Part Number	700660215
-----------------	-----------

Reference - Drawing Numbers

Product Specification	PS-70058, PS-70400, PS-71851
Sales Drawing	SD-70066-0211-0234
Test Summary	TS-70058-001

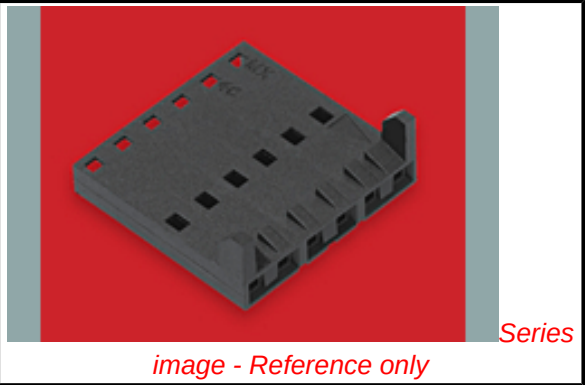

EU RoHS

**ELV and RoHS
Compliant**
REACH SVHC
Contains SVHC: No
Low-Halogen Status
Not Low-Halogen

China RoHS



**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of
Compliance, [click here](#)

Please visit the [Contact Us](#) section for any
non-product compliance questions.

Search Parts in this Series

[70066Series](#)

Mates With

6373 Straight Header, [7478](#) , [171856](#) ,
[171857](#)

Use With

SL™ Crimp Terminal [70058](#) , [71851](#)