

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [19007-0024](#)
Status: **Active**
Overview: [Quick-Disconnect Terminals](#)
Description: Flag InsulKrimp™ Quick Disconnect, Female, for 14-16 (2.00-1.30mm²) Wire, Mylar Tape, Tab 6.35 x 0.81mm

Documents:

[Drawing \(PDF\)](#)
[Product Specification PS-19902-008 \(PDF\)](#)
[Product Specification PS-19902-011 \(PDF\)](#)
[Product Specification PS-19902-015 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR18689
UL E79133

General

Product Family Quick Disconnects
Series [19007](#)
Crimp Quality Equipment Yes
Insulated Fully
Overview [Quick-Disconnect Terminals](#)
Product Name InsulKrimp™
Type Quick Disconnect
UPC 800753031869

Physical

Barrel Type Closed
Color - Resin Blue
Flammability 94V-2
Gender Female
Glow-Wire Compliant Yes
Insulation Nylon (PA)
Lock to Mating Part None
Material - Metal Brass
Material - Plating Mating Tin
Material - Plating Termination Tin
Material - Resin Nylon
Net Weight 1.195/g
Orientation Flag
Packaging Type Adhesive Tape on Reel
Polarized to Mating Part No
Tab Thickness 0.81mm
Tab Width 6.35mm
Temperature Range - Operating -65°C to +105°C
Wire Insulation Diameter 5.08mm max.
Wire Size AWG 14, 16
Wire Size mm² 1.30 - 2.00

Electrical


Voltage - Maximum 600V

Material Info

Old Part Number BB-2221T

Reference - Drawing Numbers

Product Specification PS-19902-008, PS-19902-011, PS-19902-015
Sales Drawing SD-19007-004

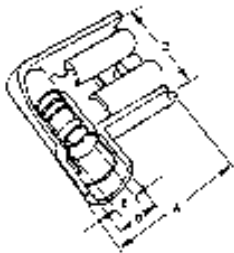

Series

image - Reference only

EU RoHS

**ELV and RoHS
Compliant**

REACH SVHC

Not Reviewed

Low-Halogen Status

Low-Halogen

China RoHS



**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of
Compliance, [click here](#)

Please visit the [Contact Us](#) section for any
non-product compliance questions.

Search Parts in this Series

[19007Series](#)

Application Tooling | FAQ

*Tooling specifications and manuals are
found by selecting the products below.
Crimp Height Specifications are then
contained in the Application Tooling
Specification document.*

Global

Description

Product #

Crimp Dies for the ATP-301 Air
Crimping Press for
Mylar Tape Mounted
Terminals [0192880165](#)

This document was generated on 01/14/2015

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION