

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 19193-0106
Status: Active
Overview: VersaKrimp™ Terminals and Splices
Description: VersaKrimp™ Ring Tongue Terminal for 10-12 AWG Wire

Documents:
[Drawing \(PDF\)](#)
[Product Specification PS-19902-011 \(PDF\)](#)
[Product Specification PS-19902-013 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR18689
UL E32244

General

Product Family Ring and Spade Terminals
Series 19193
Crimp Quality Equipment Yes
Mil-Spec N/A
Overview VersaKrimp™ Terminals and Splices
Product Name VersaKrimp™
Type Ring
UPC 800755049459

Physical


Barrel Type Closed - Brazed
Insulation None
Material - Plating Mating Tin
Net Weight 1.496/g
Packaging Type Bag
Stud Size 8 (M4)
Wire Size AWG 10, 12
Wire Size mm² 3.30 - 5.00

Material Info

Old Part Number C-328-08

Reference - Drawing Numbers

Product Specification PS-19902-011, PS-19902-013
Sales Drawing SD-19193-023

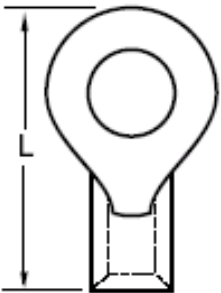

Series

image - Reference only

EU RoHS
ELV and RoHS
Compliant
REACH SVHC
Not Reviewed
Low-Halogen Status
Low-Halogen

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series
19193Series

Application Tooling | FAQ
Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.
Global

Description	Product #
PremiumGrade™	0640030100
Hand Crimp Tool	
Crimp Head for the	0640070100
AT-200™ Pneumatic	
Hand Tool	