

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

50-57-9013

Status:


Active

Overview:

SL™ Modular Connectors

Description:

SL™ Crimp Housing, Single Row, Version A, Non-polarized, 13 Circuits

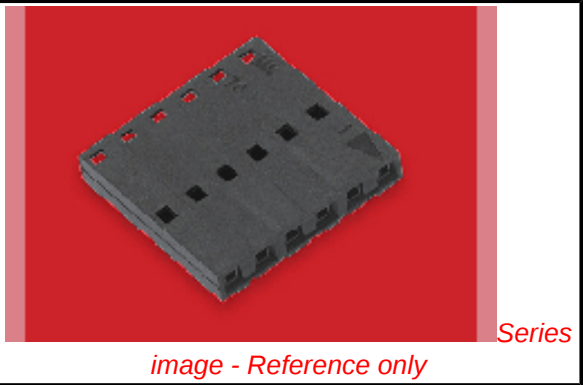

Documents:

3D Model

Drawing (PDF)

Product Specification PS-70058 (PDF)

Product Specification PS-70400 (PDF)

Product Specification PS-71851 (PDF)

Test Summary TS-70058-001 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR19980
UL	E29179
General	
Product Family	Crimp Housings
Series	70066
Application	Signal, Wire-to-Board
Comments	Version A
Overview	SL™ Modular Connectors
Product Name	SL™
UPC	800753578241
Physical	
Circuits (maximum)	13
Color - Resin	Black
Flammability	94V-0
Gender	Female
Glow-Wire Compliant	No
Keying to Mating Part	None
Lock to Mating Part	No
Material - Resin	Polyester Alloy
Net Weight	0.093/g
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.54mm
Stackable	Yes
Temperature Range - Operating	-40°C to +105°C
Electrical	
Current - Maximum per Contact	3A
Material Info	
Old Part Number	70066-0012
Reference - Drawing Numbers	
Product Specification	PS-70058, PS-70400, PS-71851
Sales Drawing	SD-70066-0001-0024
Test Summary	TS-70058-001

EU RoHS

ELV and RoHS Compliant

REACH SVHC

Contains SVHC: No

Low-Halogen Status

Not Low-Halogen

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com

For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

70066Series

Mates With

42375 , 42377 , 70280 , 70287 , 71308 , 70543 , 70553

Use With

SL™ Crimp Terminal 70058 , 71851