

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 50-57-9207
Status: Active
Overview: SL™ Modular Connectors
Description: SL™ Crimp Housing, Single Row, Version C, Front Ribs, 7 Circuits

Documents:
[3D Model](#)
[Drawing \(PDF\)](#)
[Product Specification PS-70058 \(PDF\)](#)
[Product Specification PS-70400 \(PDF\)](#)
[Product Specification PS-71851 \(PDF\)](#)
[Test Summary TS-70058-001 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR19980
UL E29179

General

Product Family Crimp Housings
Series 70066
Application Signal, Wire-to-Board
Comments Version C
Overview SL™ Modular Connectors
Product Name SL™
UPC 800753512191

Physical

Circuits (maximum) 7
Color - Resin Black
Flammability 94V-0
Gender Female
Glow-Wire Compliant No
Keying to Mating Part Yes
Lock to Mating Part No
Material - Resin Polyester Alloy
Net Weight 0.051/g
Number of Rows 1
Packaging Type Bag
Panel Mount No
Pitch - Mating Interface 2.54mm
Stackable No
Temperature Range - Operating -40°C to +105°C

Electrical


Current - Maximum per Contact 3A

Material Info

Old Part Number 70066-0076

Reference - Drawing Numbers

Product Specification PS-70058, PS-70400, PS-71851
Sales Drawing SD-70066-0071-0094
Test Summary TS-70058-001

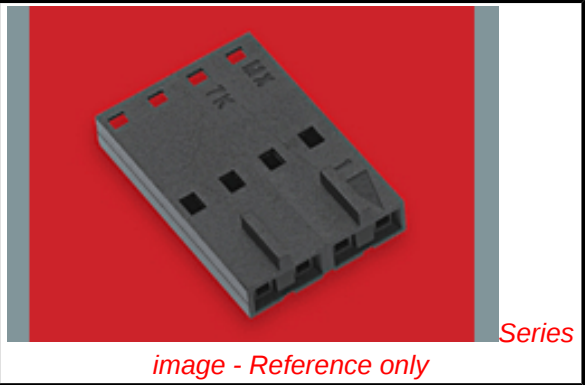

EU RoHS
ELV and RoHS
Compliant
REACH SVHC
Contains SVHC: No
Low-Halogen Status
Not Low-Halogen

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series
70066Series

Mates With
70543 , 70545 , 70553 , 70555 , 70541 ,
70551 , 70634 , 74099

Use With
SL™ Crimp Terminal 70058 , 71851