

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [50-37-5113](#)
Status: **Active**
Overview: [SPOX™ Wire-to-Board Connectors](#)
Description: 2.50mm Pitch SPOX™ Wire-to-Board Crimp Housing, Friction Lock, 11 Circuits

Documents:
[3D Model](#) [Product Specification PS-5264-001 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)


Agency Certification
UL E29179

General
Product Family Crimp Housings
Series [5264](#)
Application Signal, Wire-to-Board
Overview [SPOX™ Wire-to-Board Connectors](#)
Product Name SPOX™
UPC 800753578401

Physical
Circuits (maximum) 11
Flammability 94V-0
Gender Female
Glow-Wire Compliant No
Net Weight 594.600/mg
Number of Rows 1
Packaging Type Bag
Panel Mount No
Pitch - Mating Interface 2.50mm
Polarized to Mating Part Yes
Stackable No
Temperature Range - Operating -40°C to +105°C

Material Info
Old Part Number 5264-11

Reference - Drawing Numbers
Product Specification PS-5264-001, RPS-5264-001, RPS-5264-002, RPS-5264-003, RPS-5264-004, RPS-5264-005, RPS-5264-006
Sales Drawing SD-5264-N

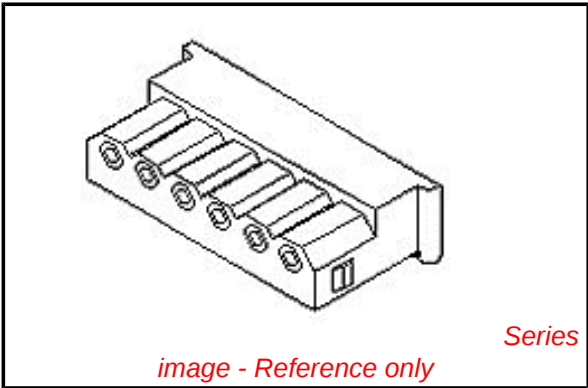

EU RoHS
ELV and RoHS
Compliant
REACH SVHC
Contains SVHC: No
Low-Halogen Status
Low-Halogen

China RoHS

Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series
[5264Series](#)

Mates With
[5267](#) vertical shrouded PCB header, [5268](#) right angle shrouded PCB header

Use With
[5263](#)