



Cat5e UTP RJ45 Male to Female Extension Cables

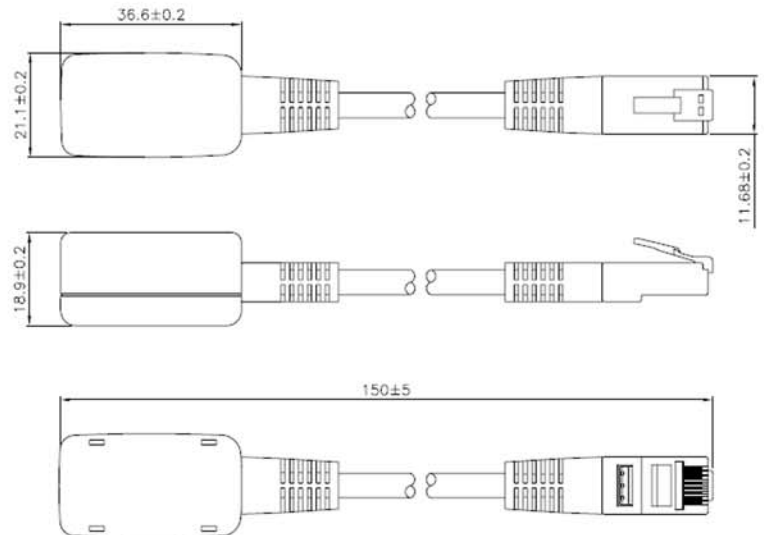

The Cat5e UTP extensions cables avoid the necessity of replacing an existing cable when additional length is required. Available in a variety of lengths, each assembly is quality manufactured and fully tested.

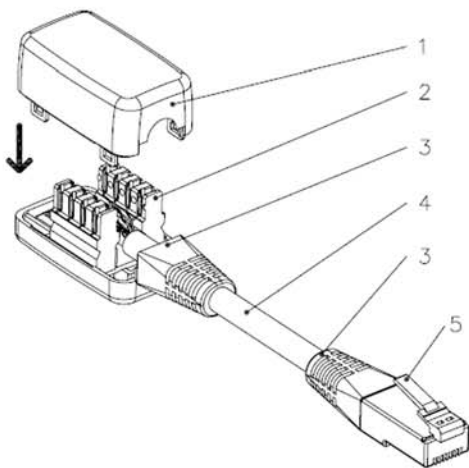

PLUG T568B		Wiring information		KEYSTONE T568B	
COLOR CODE	PIN			COLOR CODE	PIN
WHITE/ORANG	PIN.1	-----	-----	WHITE/ORANGE	PIN.1
ORANG	PIN.2	-----	-----	ORANGE	PIN.2
WHITE/GREEN	PIN.3	-----	-----	WHITE/GREEN	PIN.3
BLUE	PIN.4	-----	-----	BLUE	PIN.4
WHITE/BLUE	PIN.5	-----	-----	WHITE/BLUE	PIN.5
GREEN	PIN.6	-----	-----	GREEN	PIN.6
WHITE/BROWN	PIN.7	-----	-----	WHITE/BROWN	PIN.7
BROWN	PIN.8	-----	-----	BROWN	PIN.8

Specification :

- Material :
- Housing : ABS, UL 94V-0, Outward Matt, Grey Color.
 - IDC
 - 1 IDC Housing : Polycarbonate, UL 94V-2, KRONE dual.
 - 2 IDC Terminal material & finished : Phosphor Bronze with 50-60 micro-inch Tin-Lead plated.
 - Molding Type : Narrow Molded, PVC 70P, Grey Color.
 - Cable : min. CAT.5e Unshielded Twisted Pair, 24AWG Stranded conductor, PVC Jacket with Grey Color.
 - RJ45 Plug :
 1. Housing & Insert : Polycarbonate, UL 94V-2, Transparence color.
 2. Contact material : Phosphor Bronze with 50-60 micro-inch Nickel plated.
 3. Contact finished : min. 50 micro-inch Gold plated on contact area.