

# MIGHTYLITE LED FLOODLIGHTS WITH PIRs

Powerful security lights with built-in, fully adjustable PIRs




**1300**  
LUMENS

**16**  
WATTS

## 16W Mightylite floodlight with PIR

Super-bright **1300 lumen** floodlight with built-in PIR and frosted lens for better light dispersion. Fully adjustable PIR settings for lux level, activation time (5 seconds – 15 minutes) and range. Switched override allows light to be switched on independently of PIR activation. Available with matt black or gloss white facing.

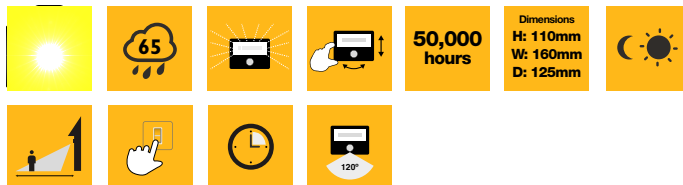


**2300**  
LUMENS

**28**  
WATTS

## 28W Mightylite floodlight with PIR

Powerful matt black floodlight which delivers **2300 lumens** of light from its wide LED array. Also features a frosted lens for better light dispersion. Fully adjustable PIR settings for lux level, activation time (5 seconds – 15 minutes) and range. Switched override allows light to be switched on independently of PIR activation.

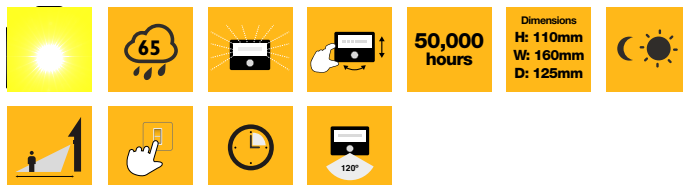


**3000**  
LUMENS

**36**  
WATTS

## 36W Mightylite floodlight with PIR

Very powerful **3000 lumen** matt black floodlight which can be mounted direct to the wall or with the multi-angle wall bracket (included) for more flexible positioning such as uplighting or downlighting. Fully adjustable PIR settings for lux level, activation time (5 seconds – 15 minutes) and range. Switched override allows light to be switched on independently of PIR activation.

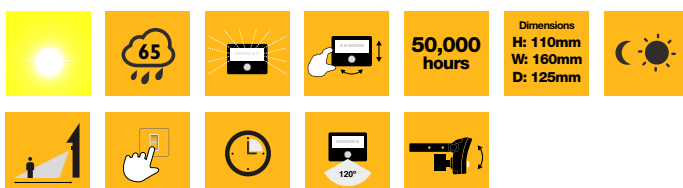

Ref.	MLF116B	MLF116W	MLF128B	MLF136B
Description	Mightylite 16W LED Floodlight with PIR	Mightylite 16W LED Floodlight with PIR	Mightylite 28W LED Floodlight with PIR	Mightylite 36W LED Floodlight with PIR
Colour	Black	White/Black	Black	Black
Lens	Frosted	Frosted	Frosted	Frosted
Lumens Generated	1300	1300	2300	3000
Voltage	230V	230V	230V	230V
IP Rating	IP65	IP65	IP65	IP65
Includes switched override	✓	✓	✓	✓
Fixing using connection box	✓	✓	✓	✓
Optional mounting bracket	✗	✗	✗	✓
PIR Angle	120°	120°	120°	120°
PIR Range	8-10m	8-10m	8-10m	8-10m
Activation Time	5secs-15mins	5secs-15mins	5secs-15mins	5secs-15mins
Dimensions (mm)	110(H) x 160(W) x 125(D)	110(H) x 160(W) x 125(D)	110(H) x 160(W) x 125(D)	110(H) x 160(W) x 130(D)