


Part Number:

T01XXXX

Type	Size	Rating	Description
LED	8mm	Various	Recessed Bezel LED with flying leads

All dimensions in mm.

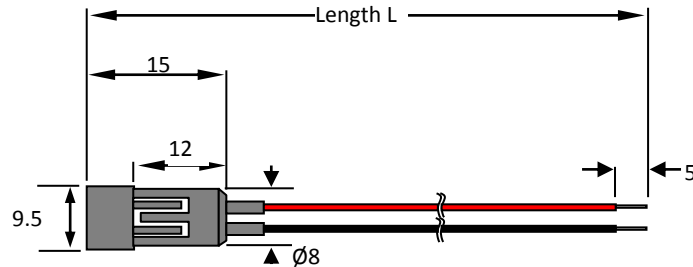

Part no.	Diameter	Length L	Colour	Volts	LED
T010005	8	500	red	NO RES	standard
T010009	8	900	red	NO RES	standard
T010015	8	500	green	NO RES	standard
T010019	8	900	green	NO RES	standard
T010025	8	500	yellow	NO RES	standard
T010029	8	900	yellow	NO RES	standard
T010105	8	500	red	6DC	standard
T010115	8	500	green	6DC	standard
T010125	8	500	yellow	6DC	standard
T010205	8	500	red	12DC	standard
T010209	8	900	red	12DC	standard
T010215	8	500	green	12DC	standard
T010219	8	900	green	12DC	standard
T010225	8	500	yellow	12DC	standard
T010229	8	900	yellow	12DC	standard
T010305	8	500	red	24DC	standard
T010309	8	900	red	24DC	standard
T010315	8	500	green	24DC	standard
T010319	8	900	green	24DC	standard
T010325	8	500	yellow	24DC	standard
T010329	8	900	yellow	24DC	standard
T011005	8	500	red	3.5-13DC	flashing
T011009	8	900	red	3.5-13DC	flashing
T011015	8	500	green	3.5-13DC	flashing
T011019	8	900	green	3.5-13DC	flashing
T011025	8	500	yellow	3.5-13DC	flashing
T011029	8	900	yellow	3.5-13DC	flashing
T011305	8	500	red	24DC	flashing
T011309	8	900	red	24DC	flashing
T011315	8	500	green	24DC	flashing
T011319	8	900	green	24DC	flashing
T011325	8	500	yellow	24DC	flashing
T011329	8	900	yellow	24DC	flashing