

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [19018-0011](#)
Status: **Active**
Overview: [Standard Quick-Disconnect Terminals](#)
Description: VibraKrimp™ Quick Disconnect, Female, for 14-16 (2.00-1.30mm²) Wire, Box, Tab 4.75 x 0.51mm

Documents:

[Drawing \(PDF\)](#)
[Product Specification PS-19902-005 \(PDF\)](#)
[Product Specification PS-19902-011 \(PDF\)](#)
[Product Specification PS-19902-013 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR18689
UL E79133

General

Product Family Quick Disconnects
Series [19018](#)
Comments Butted Seam
Crimp Quality Equipment Yes
Insulated No
Overview [Standard Quick-Disconnect Terminals](#)
Product Name VibraKrimp™
Type Quick Disconnect
UPC 800755048179

Physical

Barrel Type Closed
Gender Female
Glow-Wire Compliant No
Insulation None
Lock to Mating Part None
Material - Metal Brass
Material - Plating Mating Tin
Material - Plating Termination Tin
Net Weight 0.598/g
Orientation Straight
Packaging Type Bag
Polarized to Mating Part No
Tab Thickness 0.51mm
Tab Width 4.75mm
Temperature Range - Operating Per Wire Specification
Wire Insulation Diameter 2.10-3.70mm
Wire Size AWG 14, 16
Wire Size mm² 1.30 - 2.00

Electrical


Voltage - Maximum Per Wire Specification

Material Info

Old Part Number BB-4174

Reference - Drawing Numbers

Product Specification PS-19902-005, PS-19902-011, PS-19902-013
Sales Drawing SD-19018-001

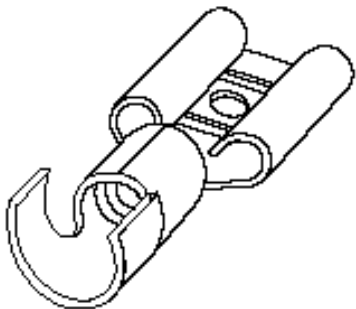

Series

image - Reference only

EU RoHS

**ELV and RoHS
Compliant**

REACH SVHC

Not Reviewed

Low-Halogen Status

Low-Halogen

China RoHS



**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of
Compliance, [click here](#)

Please visit the [Contact Us](#) section for any
non-product compliance questions.

Search Parts in this Series

[19018Series](#)

Application Tooling | FAQ

*Tooling specifications and manuals are
found by selecting the products below.
Crimp Height Specifications are then
contained in the Application Tooling
Specification document.*

Global

Description	Product #
Crimp Head for the AT-200™ Pneumatic Hand Tool	0640077200
Hand Crimp Tool	0640037200
Air Powered Crimp Tool Head	0640077300
Right Hand Crimp Tool for Female Non- Insulated Standard Quick Disconnects, 12-16 AWG Wire	0640037300

This document was generated on 02/24/2015

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION