

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

19073-0218

Status:

Active

Overview:

Solderless Terminals

Description:

Avikrimp™ Ring Tongue Terminal for 10 to 12 AWG Wire, Stud Size 6 (M3.5), Length 26.59mm, Mylar Tape Carrier

Documents:


Drawing (PDF)

Product Specification PS-19902-011 (PDF)

Product Specification PS-19902-015 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR18689
UL	E32244
General	
Product Family	Ring and Spade Terminals
Series	19073
Crimp Quality Equipment	Yes
Mil-Spec	N/A
Overview	Solderless Terminals
Product Name	Avikrimp™
Type	Ring
UPC	800753077546
Physical	
Barrel Type	Closed
Flammability	94V-2
Insulation	Nylon (PA)
Material - Plating Mating	Tin
Net Weight	2.202/g
Packaging Type	Adhesive Tape on Reel
Stud Size	6 (M3.5)
Wire Insulation Diameter	5.72mm max.
Wire Size AWG	10, 12
Wire Size mm²	3.30 - 5.00
Material Info	
Old Part Number	C-836-06T
Reference - Drawing Numbers	
Product Specification	PS-19902-011, PS-19902-015
Sales Drawing	SD-19073-008

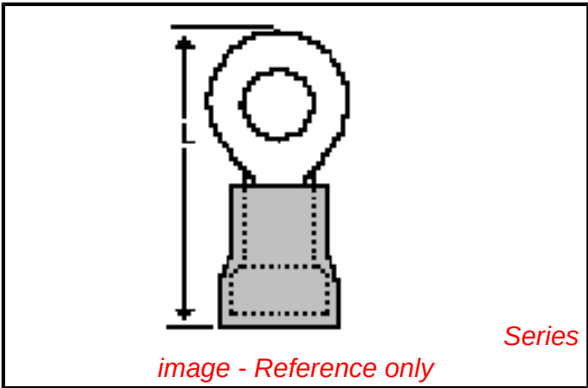

EU RoHS

ELV and RoHS Compliant

REACH SVHC

Not Reviewed

Low-Halogen Status

Low-Halogen

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com

For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

19073Series

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description	Product #
Mini-Mac™ Applicator	0638851500
Crimp Dies for MTA-100 Tape Applicator used in 3BF Press, MTA-105 Tape Applicator used in TM-2000™ Press, and ATP-301 Air Crimping Press for Mylar Tape Mounted Terminals	0192880179

This document was generated on 01/14/2015

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION