

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

19193-0091

Status:

Active

Overview:

VersaKrimp™ Terminals and Splices

Description:

VersaKrimp™ Ring Tongue Terminal for 14-16 AWG Wire

Documents:

Drawing (PDF)

Product Specification PS-19902-011 (PDF)

Product Specification PS-19902-013 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification

CSA	LR18689
UL	E32244

General

Product Family	Ring and Spade Terminals
Series	19193
Crimp Quality Equipment	Yes
Mil-Spec	N/A
Overview	VersaKrimp™ Terminals and Splices
Product Name	VersaKrimp™
Type	Ring
UPC	800755049251

Physical

Barrel Type	Closed - Brazed
Insulation	None
Material - Plating Mating	Tin
Net Weight	0.709/g
Packaging Type	Bag
Stud Size	10 (M5)
Wire Size AWG	14, 16
Wire Size mm²	1.30 - 2.00

Material Info

Old Part Number	BB-339-10
-----------------	-----------

Reference - Drawing Numbers

Product Specification	PS-19902-011, PS-19902-013
Sales Drawing	BBCD30101

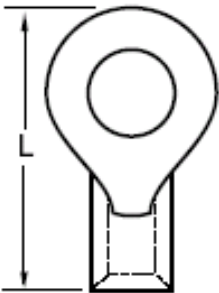


image - Reference only

EU RoHS

ELV and RoHS

Compliant

REACH SVHC

Not Reviewed

Low-Halogen Status

Low-Halogen

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series
19193Series

Application Tooling | FAQ
Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global	
Description	Product #
PremiumGrade™	0640030100
Hand Crimp Tool	
Crimp Head for the	0640070100
AT-200™ Pneumatic	
Hand Tool	

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION