

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

19198-0070

Status:

Active

Overview:

Solderless Terminals

Description:

Avikrimp™ Spade Tongue Terminal for 18-22 AWG Wire

Documents:

Drawing (PDF)

Product Specification PS-19902-011 (PDF)

Product Specification PS-19902-013 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification

CSA

LR18689

UL

E32244

General

Product Family

Ring and Spade Terminals

Series

19198

Crimp Quality Equipment

Yes

Mil-Spec

N/A

MolexKits

Yes

Overview

Solderless Terminals

Product Name

Avikrimp™

Type

Spade

UPC

800753046580

Physical

Barrel Type

Closed

Flammability

94V-0

Insulation

Nylon (PA)

Material - Plating Mating

Tin

Net Weight

0.864/g

Packaging Type

Bag

Stud Size

5-6 (M3-3.5)

Wire Insulation Diameter

3.60mm max.

Wire Size AWG

18, 20, 22

Wire Size mm²

0.35 - 0.80

Material Info

Old Part Number

AA-835-06


Reference - Drawing Numbers

Product Specification

PS-19902-011, PS-19902-013

Sales Drawing

AACD80303

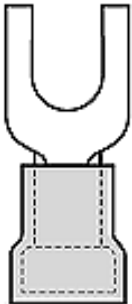

Series

image - Reference only

EU RoHS

ELV and RoHS

Compliant

REACH SVHC

Not Reviewed

Low-Halogen Status

Not Low-Halogen

China RoHS

Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series
19198Series

Application Tooling | FAQ
Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global	
Description	Product #
Crimp Head for the AT-200™ Pneumatic Hand Tool	0640050100
PremiumGrade™ Hand Crimp Tool	0640010100

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION