



Order symbol: TA090706
Product nbr: 5814038
Description: Enclosure, ABS
Remarks: Grey cover


EAN: 6418074011466
El. number:
Finland: 3438267
Electric No. Denmark: 8212045211
Electric No. Sweden: 5814038

Including: Base with PUR gasket, screws for mounting plate/DIN-rail and cover with polyamide cover screws.


Sample photo

Dimensions:		Length	Width	Height	Accessories:	
mm:		95	65	60	DRM 50	DIN-15 Mounting rail
inch:		3.7	2.6	2.4	FP 10674	
					DPS 14553	Grey sealing plug set
Materials:					Rating:	
Material:		ABS			Ingress Protection (EN 60529): IP65	
Base colour:		RAL 7035 -light grey			Impact Resistance (EN 62262): IK07	
Cover screws material:		Polyamide			Electrical insulation: Totally insulated	
Cover colour:		RAL 7035 -light grey			Halogen free (DIN/VDE 0472, Part 815): 1	
Cover screws colour:		Grey			Flammability Rating: UL 94 HB	
Gasket material:		Polyurethane			Glow Wire Test (IEC 695-2-1) °C: 650	
Temperatures:					Certificates:	
Temperature °C (short term):		-40 ... 80 °C			SGS Fimko	
Temperature °C (continuous):		-40 ... 60 °C				
Temperature °F (short term):		-40 ... 175 °F				
Temperature °F (continuous):		-40 ... 140 °F				
Accessories:						
MP 0907		Mounting plate				

TEMPO 95X65X60

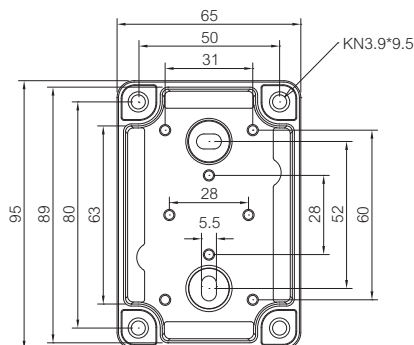

TAM

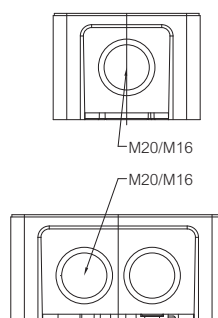

TEMPO MEMBRANE

