



Order symbol: TA131308
Product nbr: 5814041
Description: Enclosure, ABS
Remarks: Grey cover

EAN: 6418074011497
El. number:
Finland: 3438270
Electric No. 8212045240
Denmark:
Electric No. Sweden: 5814041

Including: Base with PUR gasket, screws for mounting plate/DIN-rail and cover with polyamide cover screws.

Sample photo

Dimensions:			Accessories:		
mm:	130	130	75	MIV 10	DIN-35 Mounting rail
inch:	5.1	5.1	3.0	MP 1313	Mounting plate
				FP 10674	
				DPS 14553	Grey sealing plug set
Materials:					
Material:	ABS				
Base colour:	RAL 7035 -light grey				
Cover screws material:	Polyamide				
Cover colour:	RAL 7035 -light grey				
Cover screws colour:	Grey				
Gasket material:	Polyurethane				
Temperatures:					
Temperature °C (short term):	-40 ... 80 °C				
Temperature °C (continuous):	-40 ... 60 °C				
Temperature °F (short term):	-40 ... 175 °F				
Temperature °F (continuous):	-40 ... 140 °F				
Accessories:					
DRM 100		DIN-15 Mounting rail			



Rating:

Ingress Protection (EN 60529): IP65
Impact Resistance (EN 62262): IK07
Electrical insulation: Totally insulated
Halogen free (DIN/VDE 0472, Part 815): 1
Flammability Rating: UL 94 HB
Glow Wire Test (IEC 695-2-1) °C: 650

Certificates:

SGS Fimko

TAM 1313

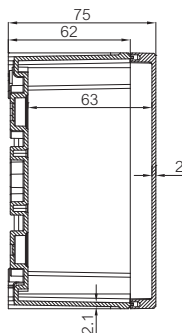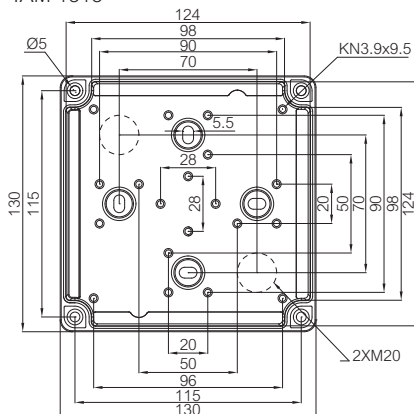

TAM

