



(2,54 mm) .100"

IPL1-120-01-L-D-RA-K

IPL1-106-01-L-D-RE1-K

IPL1-107-02-L-D-K

IPL1-110-02-L-S-K

IPL1 SERIES

DISCRETE WIRE HEADER

SPECIFICATIONS

For complete specifications
www.samtec.com?IPL1

Insulator Material:
Natural LCP

Terminal Material:
Phosphor Bronze

Plating:
Sn or Au over

50 μ" (1,27 μm) Ni

Operating Temp Range:
-55°C to +125°C

Voltage Rating:
675 VAC/954 VDC

RoHS Compliant:
Yes

Processing:
Lead-Free Solderable:

Yes

-S & -D (-02 Lead Style)

SMT Lead Coplanarity:
(0,10 mm) .004" max (02-05)

(0,13 mm) .005" max (06-10)

(0,15 mm) .006" max (11-25)

-SH SMT Lead Coplanarity:
(0,15 mm) .006" max (02-25)

Mates with:
MMSD, MMSS,
MMSDT, MMSST

Mates with
discrete wire cable
assemblies

Align &
Latch™

Keyed
Polarization

(2,54 mm)
.100" pitch

Surface Mount, Right Angle,
Right Angle Elevated
and Vertical Through-hole


RECOGNITIONS

For complete scope of
recognitions see
www.samtec.com/quality



FILE NO. E111594

-RE1 APPLICATION

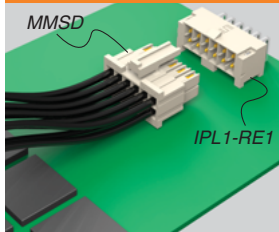

ALSO AVAILABLE (MOQ Required)

- Other sizes
- With or without plug polarization
- Guide post holes
- Other platings
- Weld tab
- Contact Samtec.

Note: Some lengths, styles and options are non-standard, non-returnable.

