

DESKTOP & INSTRUMENT CASES

1000 Series Vario Cases

ABS desk cases with inclined aluminium panel, recessed to accept membranes and overlays.


- Base moulded in high impact ABS
- Aluminium lid mounted by 4x M3 screws
- Recessed front panel to accept keypad membranes and overlays
- Polished finish for ease of cleaning
- Vertical PCB guides in base
- PCB pillars in base
- ABS UL94-V0 material optional



SPECIFICATION

| | |
|------------------------|---|
| Protection class | IP54 |
| Standard colours | Front panel grey Base grey as standard, white to order |
| Standard unit includes | Lid & base 4x M3 machine screws 4x rubber feet |

| BLACK | LIGHT GREY | LENGTH | WIDTH | HEIGHT |
|----------------|---------------|--------|-------|--------|
| BIM1005-BLK/PG | BIM1005-GY/PG | 97mm | 162mm | 57mm |
| BIM1006-BLK/PG | BIM1006-GY/PG | 130mm | 215mm | 72mm |

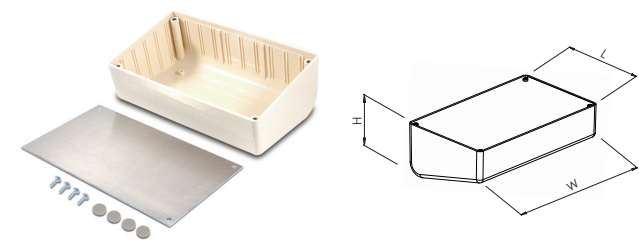

8000 Series Euro Desk Cases

ABS desktop cases with removable base plates for ease of access and flush fitting aluminium front panels.

- Moulded in high impact ABS
- Aluminium lid mounted by 4x M3 screws
- Removable base plate for ease of access and fast assembly
- Gloss finish for ease of cleaning
- Integral side PCB slots in enclosure body
- PCB pillars in base



SPECIFICATION

| | |
|------------------------|--|
| Materials | Body and base plate high impact ABS as standard UL94-V0 ABS to order Panel 1mm thick aluminium |
| Operating temperature | Resistant to temperatures up to 85°C |
| Protection class | IP40 |
| Standard colours | Body & base plate grey & black as standard, white to order Aluminium panel grey |
| Standard unit includes | Body & base plate Aluminium panel 8/10x M3 fixing screws 4x rubber feet |

| BLACK | GREY | LENGTH | WIDTH | HEIGHT |
|----------------|---------------|--------|-------|--------|
| BIM8005-BLK/PG | BIM8005-GY/PG | 127mm | 170mm | 70mm |
| BIM8007-BLK/PG | BIM8007-GY/PG | 187mm | 243mm | 103mm |

