
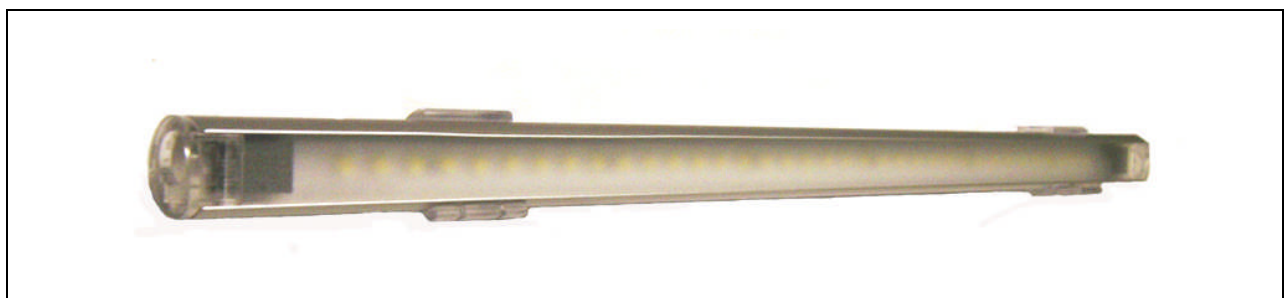


300 mm LED Light Bar (White SMD multi-LED)

LB3002006NWF

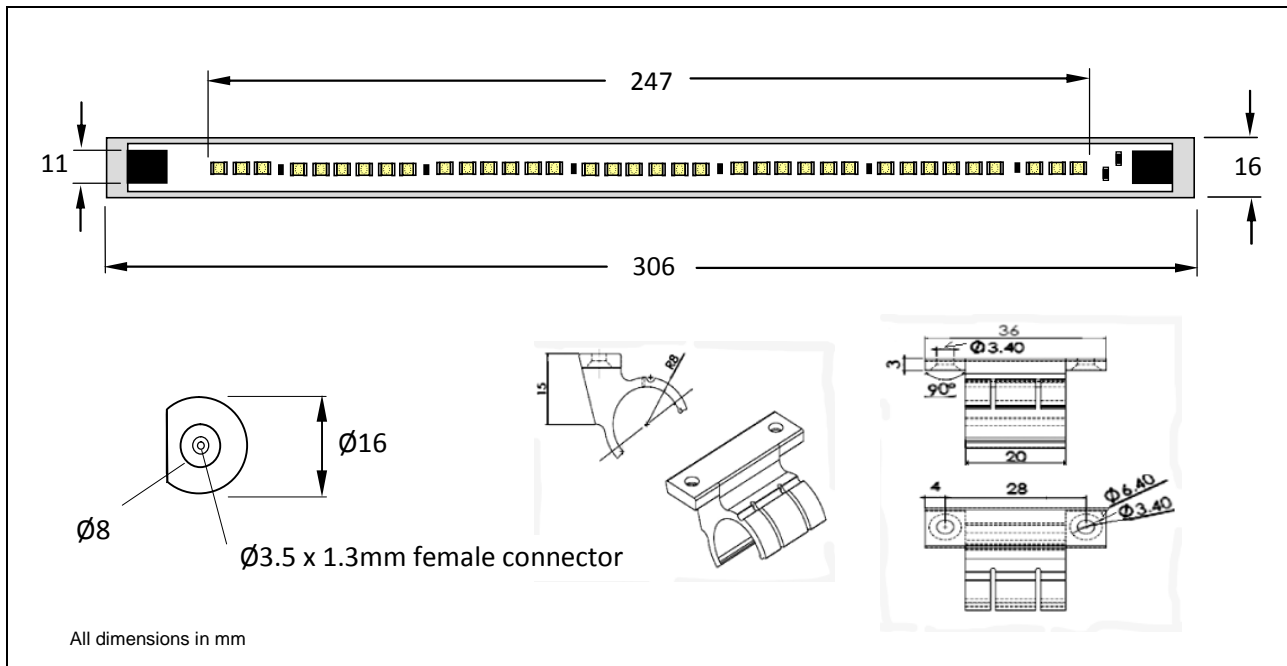

Product Characteristics

Operating Voltage:	24VDC
Power Consumption:	6W
Number of LED rows:	One
Number of LEDs:	36 x SMD3020
Overall Length:	306 mm Maximum.
Nominal Light output:	220 Lumens
Colour Temperature:	6000°K (Natural White)
Viewing Angle:	100°
Power Connector:	$\varnothing 3.5$ mm x 1.3mm
Life Duration:	20,000 hours.
Ingress Protection Rating:	IP40
Construction:	Rigid circuit board within matt aluminium casing, frosted acrylic lens cover and clear acrylic end caps.

Notes.

- 1) Light Bar supplied with two mounting clips & screws, one flexible daisy-chain connector and one rigid daisy chain connector.
- 2) RoHS compliant.