

LEDs & INDICATORS


580 Series

- Open ended body with 90° snap on lens
- Stripped 6mm wire termination 200mm long, PVC
- Neons 240V 0.8mA as standard, 125V 1mA to order
- Polysulphone body and lens
- Red, green, amber and clear lens colour options as standard
- Maximum working temperature 105°C
- Custom wire lengths and specification to order




	TYPE NO.	501	X	XX -XXXX	- T /	XXX
580 Series Indicator	580					
Lens Type	1					
Stripped wire 200mm long	05					
Neon 125V 1mA, blue wire	125					
Neon 240V 0.8mA, red wire	240					
Transparent lens	T					
Lens colour Red	RED					
Lens colour Green	GRN					
Lens colour Amber	AMB					
Lens colour Clear	CLR					

Body Profile

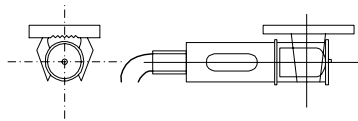

Lens Options

 

PCB
TERMINAL
BLOCKS

INTER-
CONNECTION

FUSES &
FUSE-
HOLDERS

LEDs &
INDICATORS

MINIATURE
SWITCHES

LIMIT &
SAFETY
SWITCHES

CONTROL
PRODUCTS

INTERFACE
MODULES &
SUPPORTS

RELAY
BASES

ENCLOSURES

BATTERIES

TRANS-
FORMERS



+44 (0)1638 716101
info@camdenboss.com
www.camdenboss.com

We operate a constant improvement policy,
our products are subject to change without notice.

Ver 1.0

CAMDENBOSS
ELECTRONICS & ENCLOSURES