



range introduction

The Duraplug® range of heavy duty products has become a virtual byword for durability, strength and reliability.

Duraplug® offers a wide range of products including a complete range of safety extension leads featuring rubber covered plugs, extension leads, trailing sockets, lead connectors and cable couplers. All Duraplug® products are made from top quality, high impact resistant materials such as ABS/polycarbonate and rubber.

features and benefits

- **Produced with top quality, high impact resistant materials such as ABS/polycarbonate and rubber**
- **Sockets have visible red nylon shutters**
- **Lead connectors have retaining lugs to prevent accidental disconnection**
- **All internal parts of trailing sockets are retained in the base for ease of wiring**

technical hotline +44 (0)1268 563720

portable power | wiring devices

Heavy Duty Extension Leads

13 AMP

FOUR WAY

FOUR WAY


FOUR WAY

Heavy Duty Portable Socket

13 AMP

FILTERED

FOUR WAY

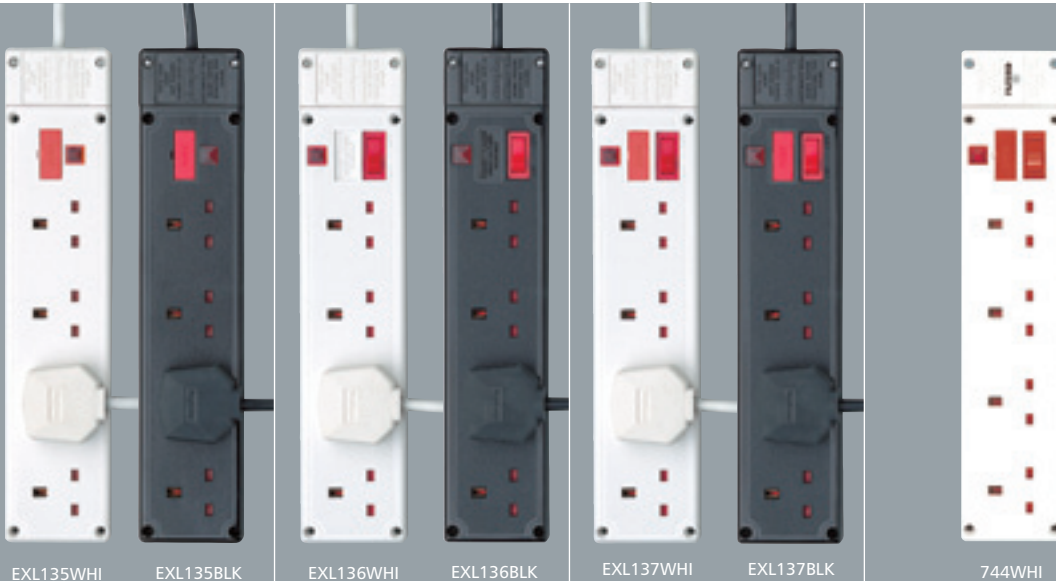

EXL135WHI EXL135BLK

13A WITH FUSE,
NEON AND 2 METRE CABLE

1
1

EXL136WHI EXL136BLK

13A WITH SWITCH,
NEON AND 2 METRE CABLE

1
1

EXL137WHI EXL137BLK

13A WITH FUSE,
SWITCH, NEON AND
2 METRE CABLE

1
1

744WHI

13A
WITH SWITCH,
NEON AND FUSE

1

Fitted with approved PVC insulated cable of appropriate core size for maximum 13A rating and a Duraplug® rubber plug.

The sockets are manufactured in high impact ABS/Polycarbonate.

BS 1363/A: Pt.2:1995

BS 6500:2000 (Table 27) / IEC 227-5

Fitted with approved PVC insulated cable of appropriate core size for maximum 13A rating and a Duraplug® rubber plug.

The sockets are manufactured in high impact ABS/Polycarbonate.

BS 1363/A: Pt.2:1995

BS 6500:2000 (Table 27) / IEC 227-5

Fitted with approved PVC insulated cable of appropriate core size for maximum 13A rating and a Duraplug® rubber plug.

The sockets are manufactured in high impact ABS/Polycarbonate.

BS 1363/A: Pt.2:1995

BS 6500:2000 (Table 27) / IEC 227-5

Fitted with a fuse carrier and 13A fuse to BS 1362. Manufactured in high impact ABS/Polycarbonate.

Can also be wall mounted.

DIMENSIONS:
317 x 68 x 31 mm

SPECIFICATION:
Max. Power 3.14kW
Response time (Varistor)
better than 20ns

BS 1363/A: Pt.2:1995

Heavy Duty Portable Socket

13 AMP

FOUR WAY



FC4134WHI

FC4134BLK

FOUR WAY



FC4135WHI

FC4135BLK

FOUR WAY



FC4136WHI

FC4136BLK

Heavy Duty Trailing Sockets

13 AMP

SINGLE & DOUBLE



FC133WHI



FC133ORG



FC133BLK



FCT133WHI



FCT133BLK



FC153BLK

FC4134WHI
FC4134BLK

 13A
 WITH FUSE
 AND NEON

1
1
FC4135WHI
FC4135BLK

 13A
 WITH SWITCH
 AND NEON

1
1
FC4136WHI
FC4136BLK

 13A
 WITH SWITCH,
 FUSE AND NEON

1
1
FC133WHI
FC133BLK
FC133ORG

 13A
 SINGLE OUTLET

10
10
10
FCT133WHI
FCT133BLK
FCT133ORG

 13A
 TWIN OUTLET

10
10
10
FC153BLK
 15A
 SINGLE OUTLET
 ROUND PIN
10
 Manufactured in high impact ABS/
 Polycarbonate
 incorporating optional wall
 mounting holes and equal length
 wire stripping.

 DIMENSIONS:
 317 x 68 x 31mm
 BS 1363/A: Pt.2:1995

 Manufactured in high impact ABS/
 Polycarbonate
 incorporating optional wall
 mounting holes and equal length
 wire stripping.

 DIMENSIONS:
 317 x 68 x 31mm
 BS 1363/A: Pt.2:1995

 Manufactured in high impact ABS/
 Polycarbonate
 incorporating optional wall
 mounting holes and equal length
 wire stripping.

 DIMENSIONS:
 317 x 68 x 31mm
 BS 1363/A: Pt.2:1995

 FC133 and FCT133
 Manufactured from tough
 Polypropylene with rubber cover.
 All internal component parts are
 retained in the base for ease of
 wiring.

BS 1363/A: Pt.2:1995

 FC153
 Rubber cover.
 BS 546:1950

 DIMENSIONS:
 FC133: 79 x 62 x 29mm
 FCT133: 80 x 125 x 29mm
 FC153: 67 x 53 x 33mm

technical hotline +44 (0)1268 563720

portable power | wiring devices

Lead Connectors

10 AMP
TWO & THREE PIN

SPARES

Rubber Plugs

Cable Couplers



LCP102BLK



LCP102PBLK



LCP102SBLK



LCP103SBLK



LCP103PBLK



LCP103PWHI



PF133WHI



PF133ORG



P153BLK



CCP53BLK



CCP153BLK


LCP102BLK
LCP102ORG

TWO PIN 10A
PLUG AND SOCKET

LCP103WHI
LCP103BLK

THREE PIN 10A
PLUG AND SOCKET

10
10

LCP102PBLK
LCP102PORG

10A PLUG TWO PIN

LCP102SBLK
LCP102SORG

10A SOCKET TWO PIN

10
10

LCP103PWHI
LCP103PBLK

10A PLUG THREE PIN

LCP103SWHI
LCP103SBLK

10A SOCKET THREE PIN

10
10

P53BLK
5A ROUND PIN

PF133WHI
PF133ORG
PF133BLK
FITTED WITH
13A FUSE

P153BLK
15A ROUND PIN

10
10
10

CCP53BLK
5A
PLUG & SOCKET

CCP153BLK
15A
PLUG & SOCKET

CCP133PBLK
SPARE 13A PLUG

1
1
1

This range of connectors provides a safe and easy method of extending power cables and electrical tools and appliances. With rubber cover and polypropylene inserts with integral cable grips. Retaining lugs prevent accidental disconnection.

Two pin versions are only for use with double insulated Class 2 appliances.

Three pin versions must be used with earthed appliances.

DIMENSIONS:
40 x 25 x 80mm

BS 5733: 2010

Comply with IP44 Ingress
Protection rating to
BS EN 60529:1992

BS 5733: 2010

Comply with IP44 Ingress
Protection rating to
BS EN 60529:1992

BS 5733: 2010

Comply with IP44 Ingress
Protection rating to
BS EN 60529:1992

PF133 With rubber cover.
Available with alternative fuse
ratings to special order only.
Approved by ASTA Licence no.470
BS 1363/A Pt.1:1995

P53BLK Manufactured in rubber

P153BLK With rubber cover and
ABS/Polycarbonate base.

BS 546:1950

These splashproof couplers are a rugged means of connecting cables in industrial and commercial environments. Fitted with heavy duty cable clamps, tapered cable entry and fuse (13A version only).

DIMENSIONS:
Diameter x Length
CCP53: 60 x 173mm
CCP133: 65 x 182mm
CCP153: 68 x 180mm

BS 5733: 2010
(BS 1363 Pin centres for
13A versions)
BS 5733: 2010
(BS 546 Pin centres for
5 and 15A versions)



range introduction

Established range of plugs and adaptors. The established names of Safetyplug™ and Toughplug™ strengthen MK's reputation for high quality products with the accent on safety and quality.

Safetyplugs

Toughplugs

NON STANDARD



646WHI 10
646CHA 10
 FITTED WITH 13A FUSE
64603WHI 10
 FITTED WITH 3A FUSE
645NIP 100
 SECRET SCREW FOR
 SAFETYPLUG AND TOUGHPLUG
644ZIC 10
 KEY FOR SECRET SCREW

647WHI 10
647CHA 10
 FITTED WITH 13A FUSE
655WHI 10
 FITTED WITH 13A FUSE
65503WHI 10
 FITTED WITH 3A FUSE
655BLK 10
655ORG 10
655RED 10
 FITTED WITH 13A FUSE
655D8WHI 10
655D8RED 10
 MARKED 'HOSPITAL PROPERTY'.
 FITTED WITH 13A FUSE

See page 206 for spare fuse links.
 BS 1363 Pt.1: 1995

See page 206 for spare fuse links.
 For use only with MK non-standard
 13A socket outlets.

See page 206 for spare fuse links.
 BS 1363/A Pt.1: 1995

BS1363 Pt1: 1995 (where relevant)

technical hotline +44 (0)1268 563720

portable power | wiring devices

Round Pin Plugs

Plug Adaptors



505WHI



515WHI



641WHI



690WHI



692WHI



696WHI



698PPK

502WHI
2A

10

505WHI
5A

10

515WHI
15A
RESILIENT COVER

10

639WHI
2A FUSED

10

641WHI
5A FUSED

10

643WHI
15A
FITTED WITH 5A FUSE

10

690WHI
13A
WITH 1 X 13A
AND 1 COMBINED 16A UNIVERSAL
AND GERMAN TYPE 2P+E
SOCKET OUTLET
FUSED 13A

5

692WHI
13A
WITH 3 X 13A SOCKET OUTLETS
FUSED 13A

5

696WHI
13A
WITH 2 X 13A SOCKET OUTLETS
UNFUSED

5

698PPK
13A
WITH 1 X 1A
SHAVER SOCKET OUTLET
FUSED 1A

10

See page 206 for spare fuse links
to BS 646.
BS 546: 1950

BS 1363 Pt.3: 1995

BS 1363 Pt.3: 1995