



RE315-HP

- SRBP paper FR2 1.50 mm
- Single-sided 35 µm Cu
- Organic soldering protection (OSP)
- Hole spacing 2.54 x 2.54 mm
- Hole diameter 1.00 mm
- Connector 32/64/96-channel DIN 41612 type C
- Size 100 x 160 mm

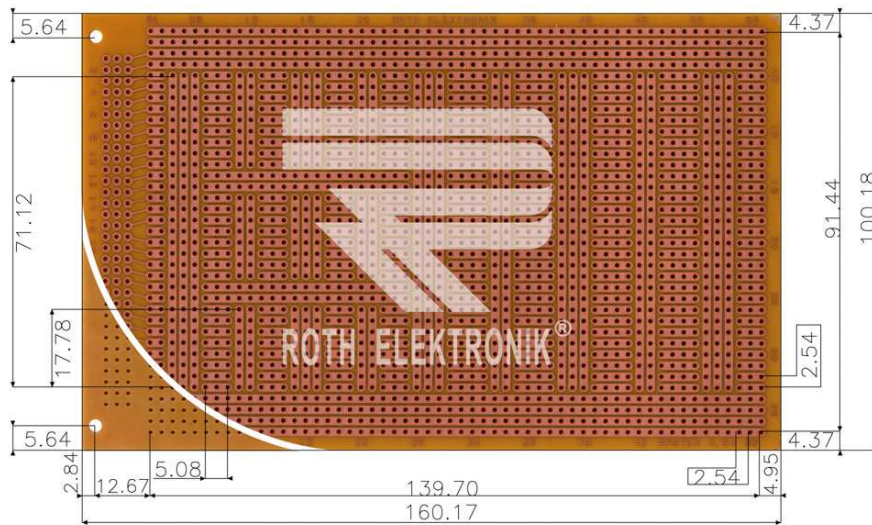


RE315-HP

- Phenolharz-Hartpapier FR2 1,50 mm
- Einseitig 35 µm Cu
- Organischer Oberflächenschutz (OSP)
- Lochraster 2,54 x 2,54 mm
- Lochdurchmesser 1,00 mm
- Steckverbinder 32/64/96-polig DIN 41612 Bauform C
- Größe 100 x 160 mm

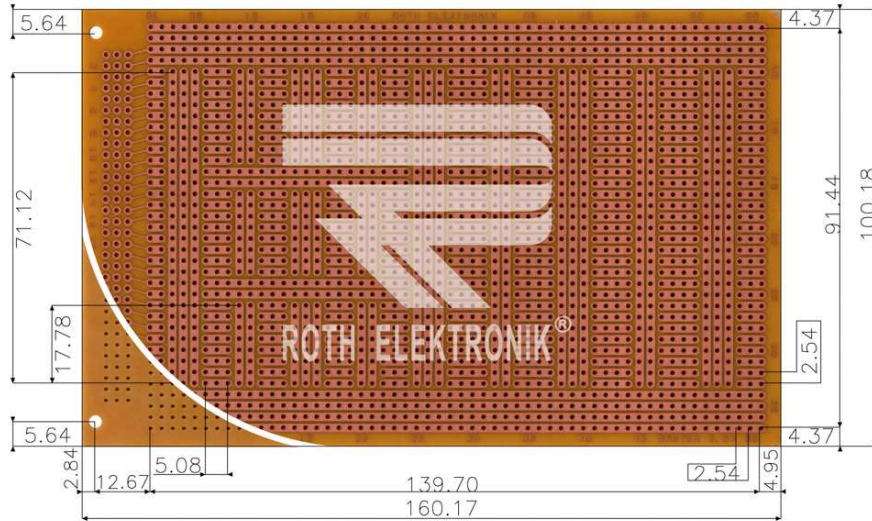

RE315-HP

- Résine phénolplaste FR2 1,50 mm
- Simple face 35 µm Cu
- Protection organique de la surface (OSP)
- Pas 2,54 x 2,54 mm
- Perforation 1,00 mm Ø
- Connecteur 32/64/96-pôles DIN 41612 type C
- Dimensions 100 x 160 mm

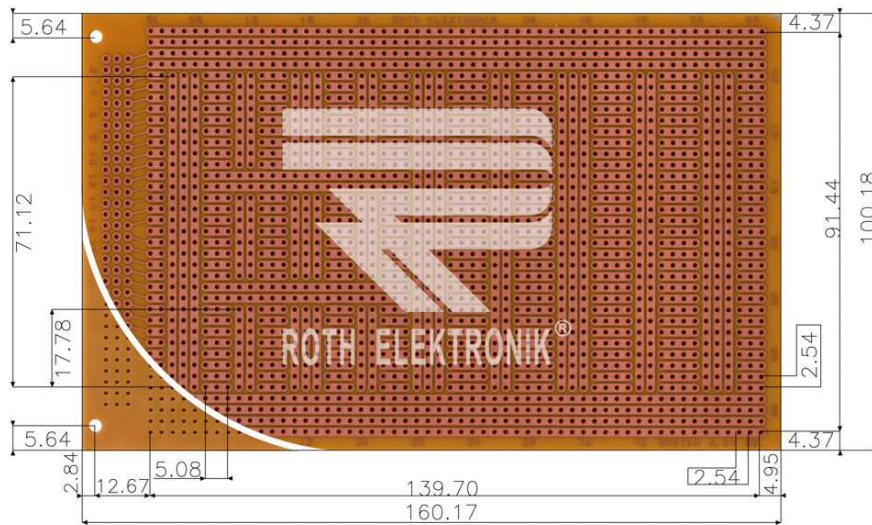

RE315-HP

- Papel endurecido con resina fenolada FR2 1,50 mm
- Por un lado 35 µm de Cu
- Protección orgánica de la superficie (OSP)
- Trama de agujeros 2,54 x 2,54 mm
- Diámetro de los agujeros 1,00 mm
- Conector enchufable 32/64/96 polos DIN 41612 modelo C
- Tamaño 100 x 160 mm