



RE1230-LF

- Epoxy fibre-glass FR4 0.80 mm
- Single-sided 35 µm Cu
- Without holes
- Hot air leveling (HAL-leadfree)
- 17 self-adhesive strips with potential strips
- Pre-scratched rated break point for the separation of individual modules from the board
- Size 90 x 100 mm

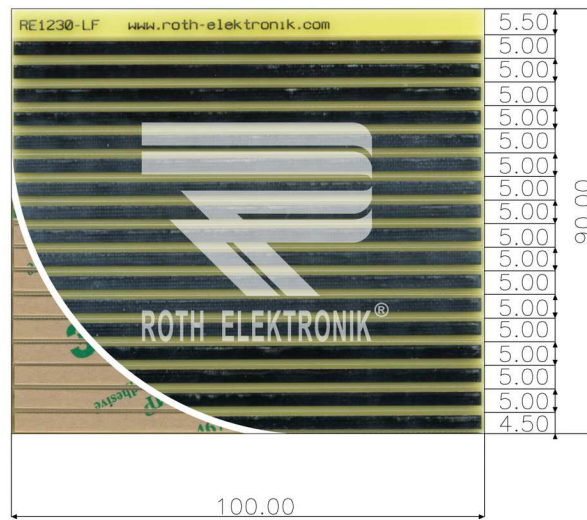

RE1230-LF

- Epoxydglashartgewebe FR4 0,80 mm
- Einseitig 35 µm Cu
- Keine Bohrungen
- Heißverzinkt (HAL-leadfree)
- 17 selbstklebende Kontakteleisten mit Potentialbahnen
- Vorgeritzte Sollbruchstellen
- Größe 90 x 100 mm

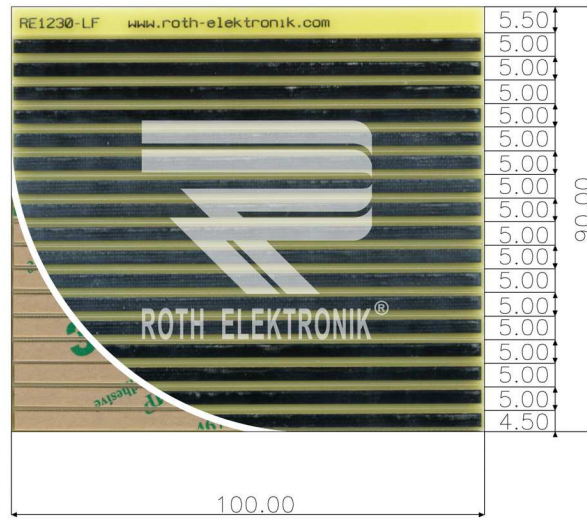

RE1230-LF

- Fibra de vidrio epoxídica FR4 0,80 mm
- Por dos lados 35 µm de Cu
- Sin agujeros
- Estañado en caliente (HAL-leadfree)
- 17 adaptadores autoadhesivos con vías de potencial
- Punto de rotura controlada tallado
- Tamaño 90 x 100 mm