



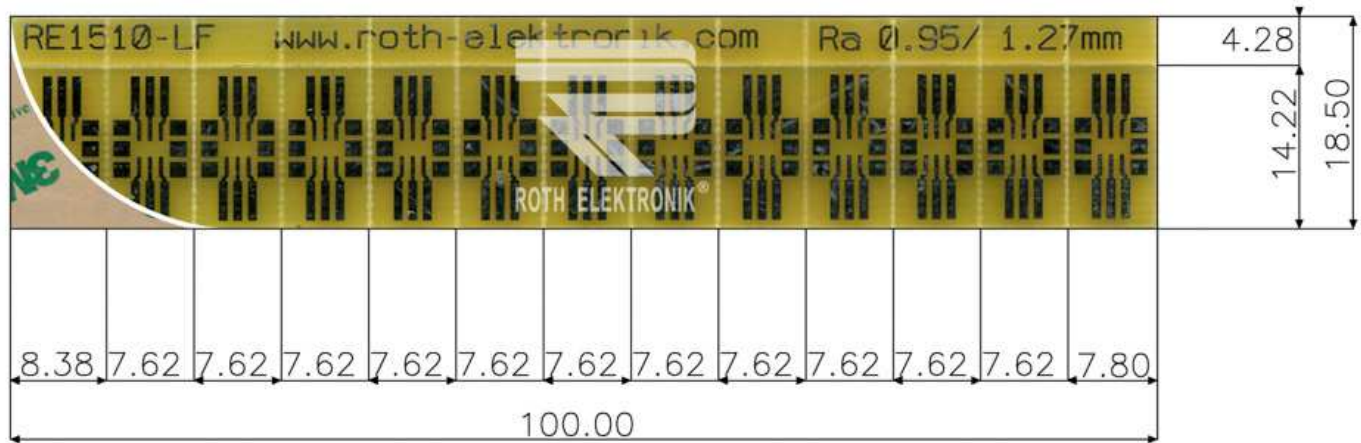

RE1510-LF

- Epoxy fibre-glass FR4 0.80 mm
- Single-sided 35 µm Cu
- Without holes
- Hot air leveling (HAL-leadfree)
- 13 self-adhesive SOT323-Adapters
- Pre-scratched rated break point for the separation of individual modules from the board
- Size 18.50 x 100.00 mm


ver.20150130

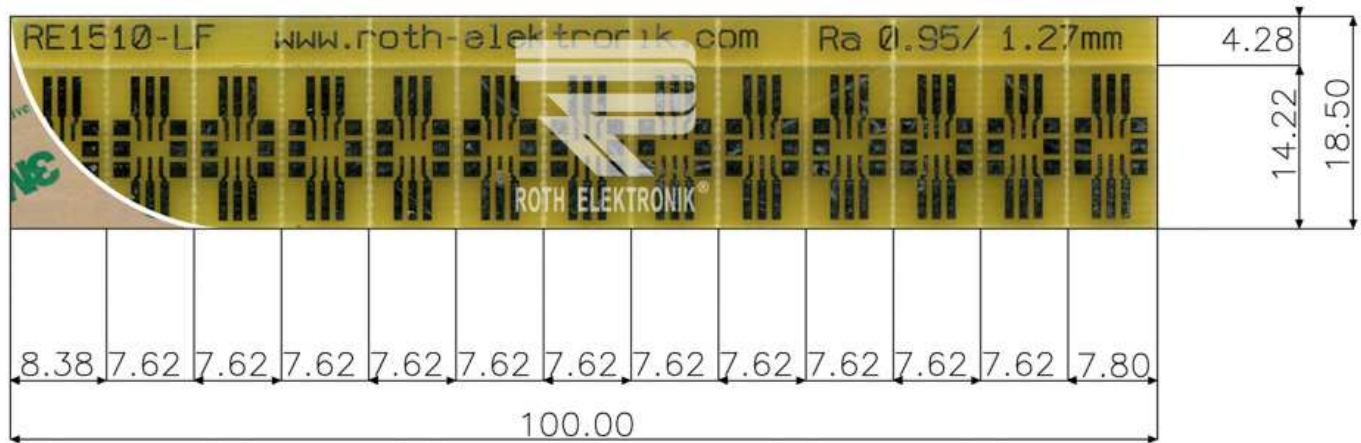

RE1510-LF

- Epoxydglashartgewebe FR4 0,80 mm
- Einseitig 35 µm Cu
- Keine Bohrungen
- Heißverzinnt (HAL-leadfree)
- 13 selbstklebende SOT323-Adapter
- Vorgeritzte Sollbruchstellen
- Größe 18,50 x 100,00 mm


ver.20150130

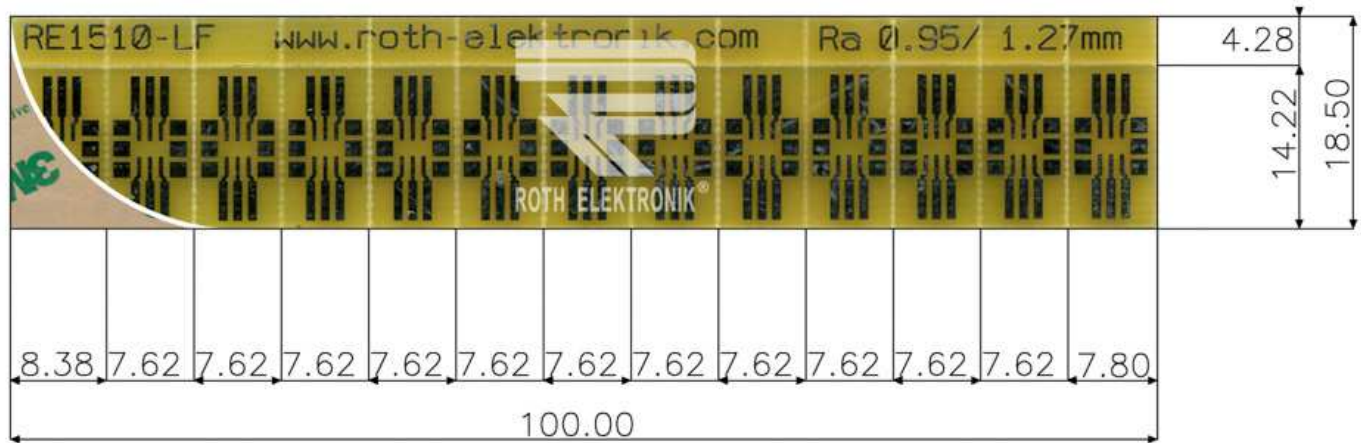

RE1510-LF

- Fibre de verre époxyde FR4 0,80 mm
- Simple face 35 µm Cu
- Sans trous
- Étamée à chaud (HAL-leadfree)
- 13 adaptateurs SOT323 autoadhésifs
- Points destinés à la rupture
- Dimensions 18,50 x 100,00 mm

ver.20150130

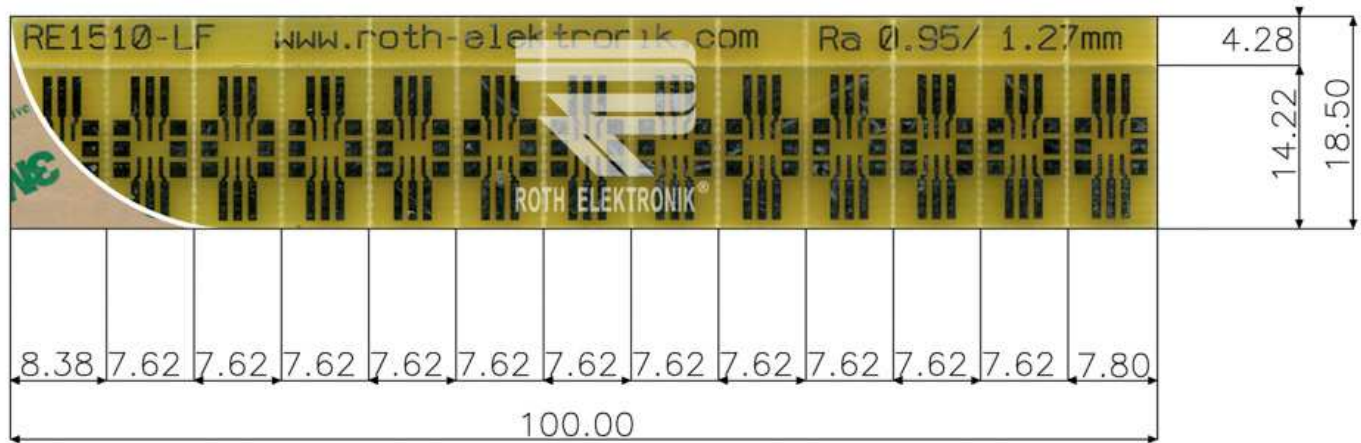

RE1510-LF

- Fibra de vidrio epoxídica FR4 0,80 mm
- Por dos lados 35 µm de Cu
- Sin agujeros
- Estañado en caliente (HAL-leadfree)
- 13 adaptadores autoadhesivos tipo SOT323
- Punto de rotura controlada tallado
- Tamaño 18,50 x 100,00 mm

ver.20150130