



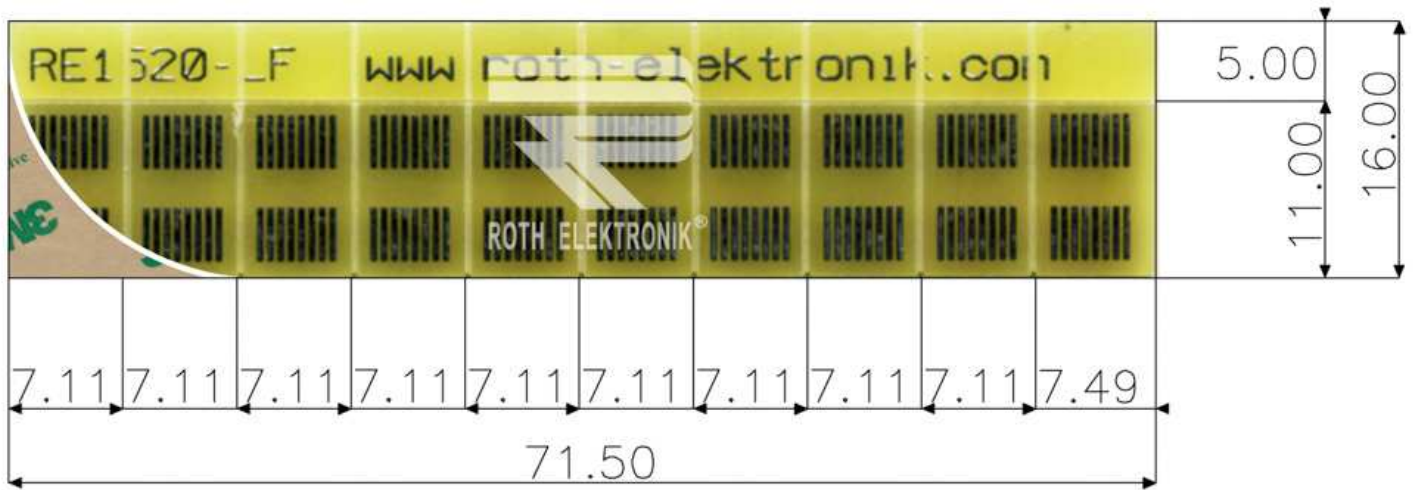

RE1520-LF

- Epoxy fibre-glass FR4 0.80 mm
- Single-sided 35 µm Cu
- Without holes
- Hot air leveling (HAL-leadfree)
- 10 self-adhesive MSOP8- & MSOP16-Adapters
- Pre-scratched rated break point for the separation of individual modules from the board
- Size 16.00 x 71.50 mm


ver.20150130

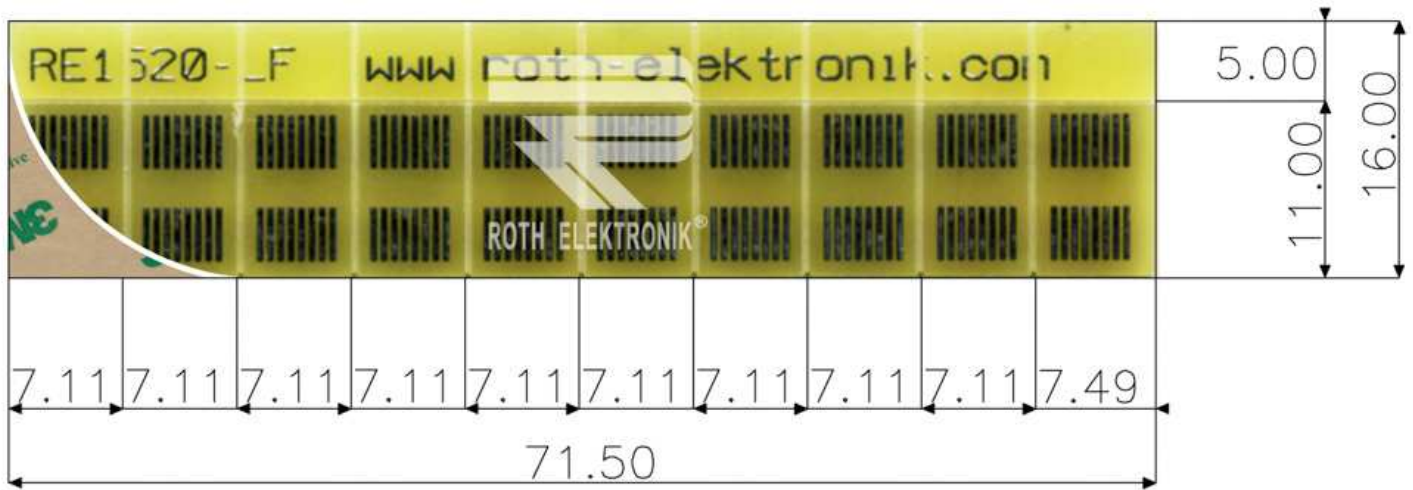

RE1520-LF

- Epoxydglashartgewebe FR4 0,80 mm
- Einseitig 35 µm Cu
- Keine Bohrungen
- Heißverzinnt (HAL-leadfree)
- 10 selbstklebende MSOP8- & MSOP16-Adapter
- Vorgeritzte Sollbruchstellen
- Größe 16,00 x 71,50 mm


ver.20150130

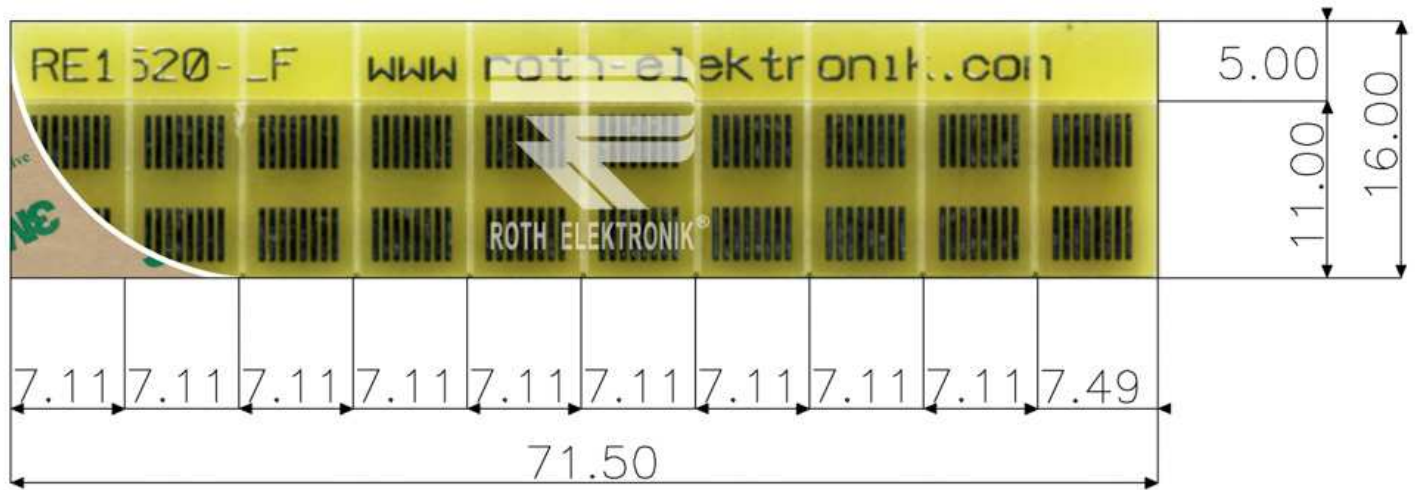

RE1520-LF

- Fibre de verre époxyde FR4 0,80 mm
- Simple face 35 µm Cu
- Sans trous
- Étamée à chaud (HAL-leadfree)
- 10 adaptateurs MSOP8- & MSOP16 autoadhésifs
- Points destinés à la rupture
- Dimensions 16,00 x 71,50 mm

ver.20150130

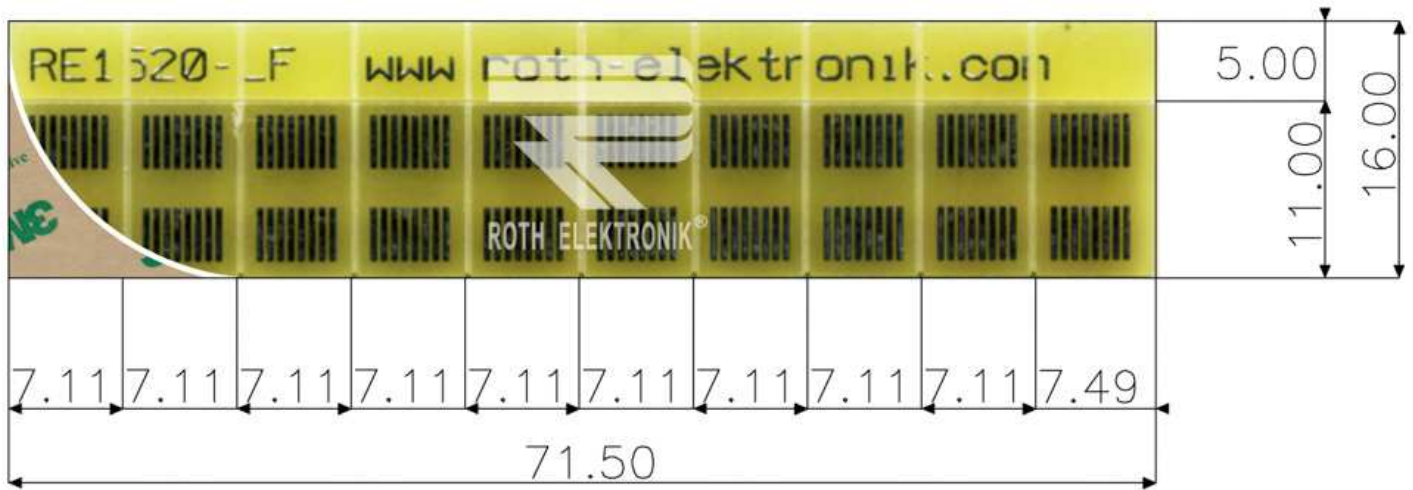

RE1520-LF

- Fibra de vidrio epoxídica FR4 0,80 mm
- Por dos lados 35 µm de Cu
- Sin agujeros
- Estañado en caliente (HAL-leadfree)
- 10 adaptadores autoadhesivos tipo MSOP8 y MSOP16
- Punto de rotura controlada tallado
- Tamaño 16,00 x 71,50 mm

ver.20150130