



#### RE200-DSPT

- Epoxy fibre-glass FR4 1.50 mm
- Double-sided 35 µm Cu
- Plated through holes (PTH)
- Hot air leveling (HAL-leadfree)
- Hole spacing 2.54 x 2.54 mm
- 38 x 61 soldering pads 2.20 mm Ø
- Hole diameter 1.00 mm
- Size 100 x 160 mm

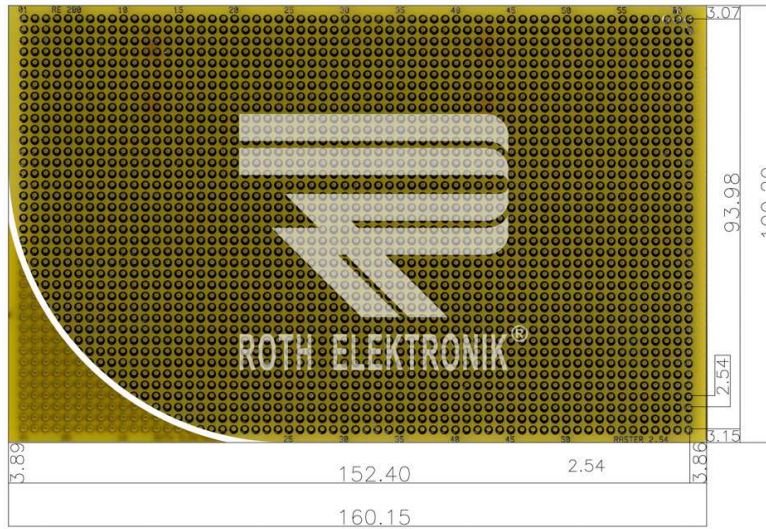


#### RE200-DSPT

- Epoxydglashartgewebe FR4 1,50 mm
- Zweiseitig 35 µm Cu
- Durchkontaktiert (PTH)
- Heißverzinkt (HAL-leadfree)
- Lochraster 2,54 x 2,54 mm
- 38 x 61 Lötinseln 2,20 mm Ø
- Lochdurchmesser 1,00 mm
- Größe 100 x 160 mm

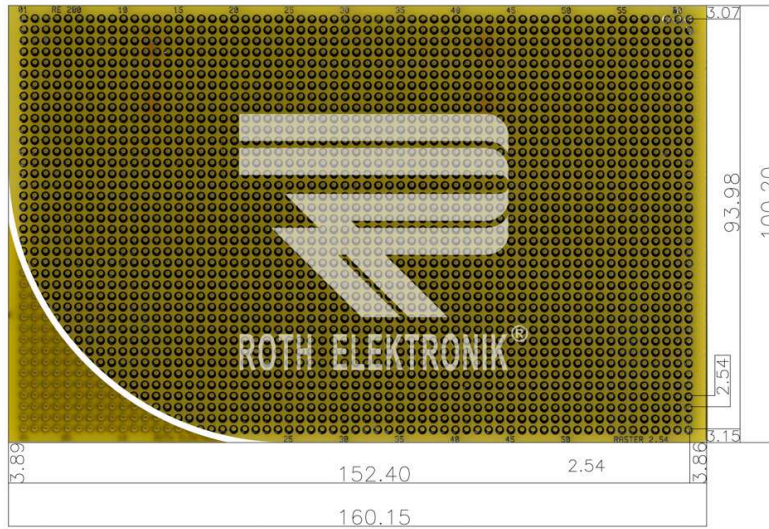

#### RE200-DSPT

- Fibre de verre époxyde FR4 1,50 mm
- Double face 35 µm Cu
- Métallisation des trous (PTH)
- Étamé à chaud (HAL-leadfree)
- Pas 2,54 x 2,54 mm
- 38 x 61 îlots de brasage 2,20 mm Ø
- Perforation 1,00 mm Ø
- Dimensions 100 x 160 mm

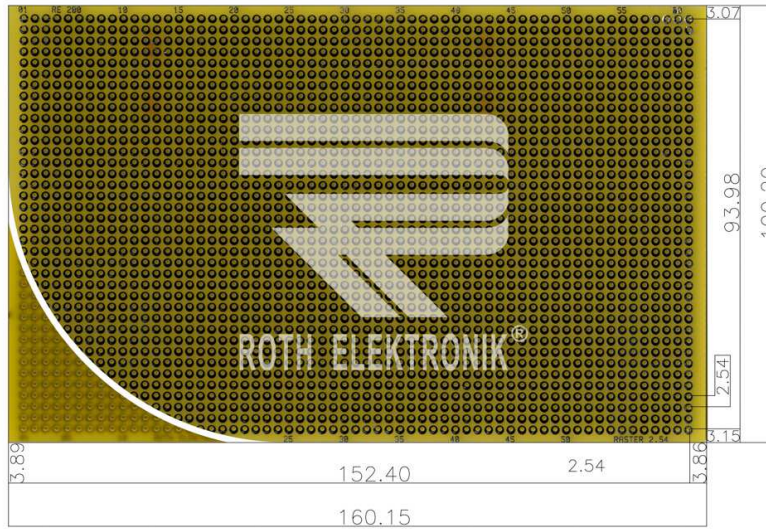

#### RE200-DSPT

- Fibra de vidrio CEM3 1,50 mm
- Por dos lados 35 µm de Cu
- Agujeros con contactos metalizados (PTH)
- Estañado en caliente (HAL-leadfree)
- Trama de agujeros 2,54 x 2,54 mm
- 38 x 61 nodos de soldadura 2,20 mm Ø
- Diámetro de los agujeros 1,00 mm
- Tamaño 100 x 160 mm