

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [51005-0400](#)
Status: **Active**
Description: 2.00mm Pitch Wire-to-Wire Receptacle Housing, 4 Circuits

Documents:

[3D Model](#)
[Drawing \(PDF\)](#)
[Product Specification PS-51005-001 \(PDF\)](#)
[Packaging Specification SPK-51005-001 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR19980
UL E29179

General

Product Family Crimp Housings
Series [51005](#)
Application Signal, Wire-to-Wire
MolexKits Yes
Product Name N/A
UPC 800753576063

Physical

Circuits (maximum) 4
Color - Resin Natural
Flammability 94V-0
Gender Female
Glow-Wire Compliant No
Lock to Mating Part None
Material - Resin Polyester
Net Weight 135.860/mg
Number of Rows 1
Packaging Type Bag
Panel Mount No
Pitch - Mating Interface 2.00mm
Stackable No
Temperature Range - Operating -40°C to +105°C


Electrical

Current - Maximum per Contact 2.0A

Material Info

Reference - Drawing Numbers

[Packaging Specification](#) SPK-51005-001
[Product Specification](#) PS-51005-001, RPS-51005-001, RPS-51005-002
[Sales Drawing](#) SD-51005-001

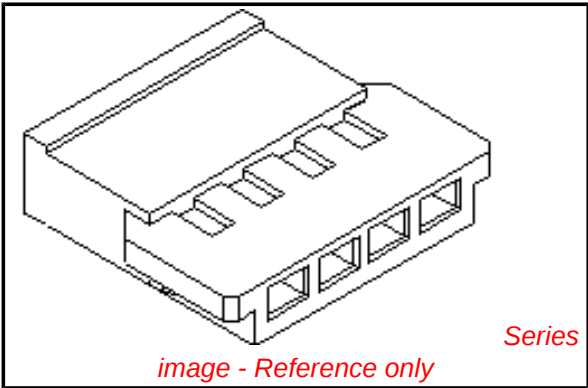

EU RoHS

**ELV and RoHS
Compliant**
REACH SVHC
Contains SVHC: No
Low-Halogen Status
Not Low-Halogen

China RoHS



**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of
Compliance, [click here](#)

Please visit the [Contact Us](#) section for any
non-product compliance questions.

Search Parts in this Series
[51005Series](#)

Mates With
[51006](#) Male Housing

Use With
[50013](#)