


CHARACTERISTICS:

MATERIAL:
COLOR: BLACK
STYLE: UL1007

ENVIRONMENTAL
OPERATING TEMPERATURE: -20°C UP TO 80°C
COMPLIANCE: LEAD FREE AND ROHS

WIRE DIMENSION:
AWG: 30

PACKAGING:
10 PCS/BAG

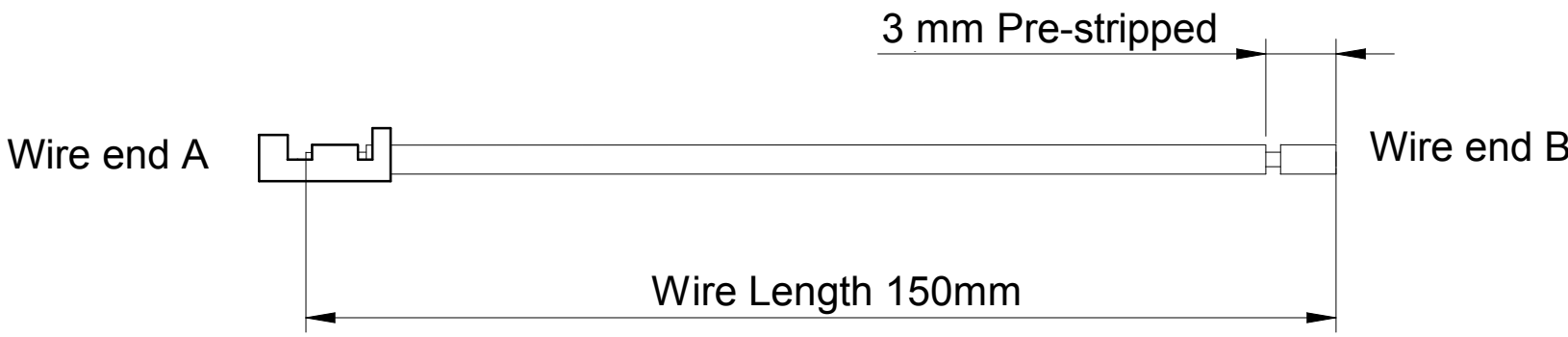


 
Wire end A	65300113722
Wire end B	Pre-stripped

RoHS Compliant				PROJECTION:	GENERAL TOLERANCE .X = $\pm$ 0.2 .XX = $\pm$ 0.15			
G								
F								
E								
D								
C				APPROVAL: RJ	UNIT: MM	DESCRIPTION: 1.25 MM PRE-CRIMPED CONTACT		SIZE A4
B	07-AUG-13	CHARACTERISTIC	QL		SCALE:			
A	18-OCT-11	PDF	GG		SHEET: 1/2	WERI PART NO: 653100130015		
REV	DATE	FILE	BY		DRAW: QL			

Note:
1.Dimension
Carton Size:40*30*20(CM)

2.Quantity: 5000 Pcs/Carton

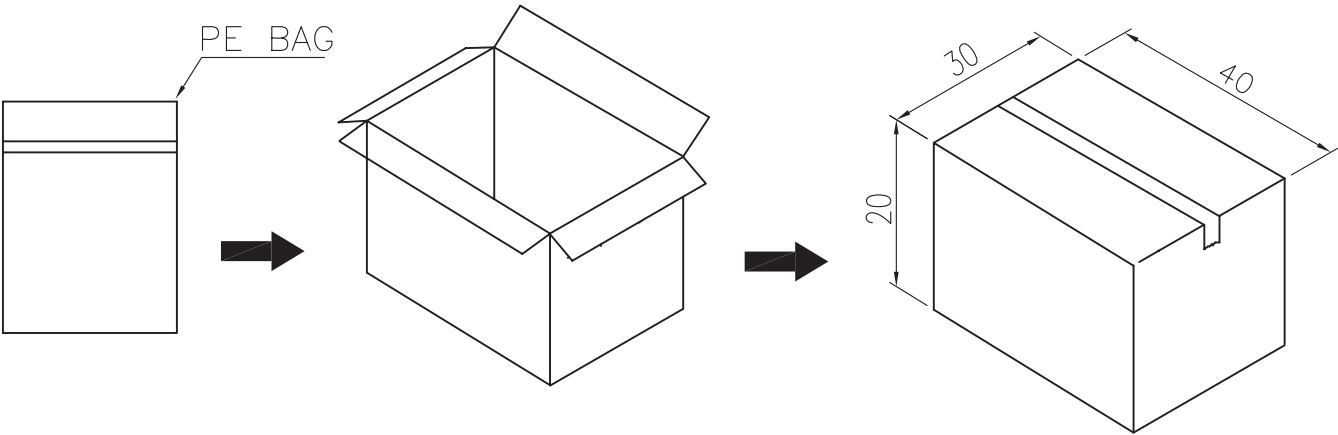

RoHS Compliant				PROJECTION: 	GENERAL TOLERANCE .X = $\pm$ 0.2 .XX = $\pm$ 0.15			
G								
F								
E								
D								
C				APPROVAL: RJ	UNIT: MM	DESCRIPTION: WR-WTB 1.25 MM PRE-CRIMPED CONTACT		SIZE A4
B					SCALE:			
A					SHEET: 2/2			
REV	DATE	FILE	BY		DRAW: QL			