

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [19274-0002](#)  
**Status:** **Active**  
**Overview:** Quixon™ Terminals  
**Description:** Quixon Quick Disconnect, InsulKrimp™ Style, Female, Partially Insulated Red, 18-22 AWG, Loose

**Documents:**

[Drawing \(PDF\)](#) [Product Specification PS-19902-013 \(PDF\)](#)  
[Product Specification PS-19902-011 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

**Agency Certification**

CSA LR18689  
 UL E79133

**General**

Product Family Quick Disconnects  
 Series [19274](#)  
 Comments Low Insertion Force  
 Crimp Quality Equipment Yes  
 Insulated Partial  
 Overview [Quixon™ Terminals](#)  
 Product Name InsulKrimp™, Quixon  
 Type Quick Disconnect  
 UPC 884982564961

**Physical**

Barrel Type Closed  
 Color - Resin Red  
 Flammability 94V-0  
 Gender Female  
 Glow-Wire Compliant No  
 Insulation PVC  
 Lock to Mating Part None  
 Material - Metal Brass  
 Material - Plating Mating Tin  
 Material - Plating Termination Tin  
 Net Weight 0.713/g  
 Orientation Straight  
 Packaging Type Bag  
 Tab Thickness 0.41mm  
 Tab Width 7.87mm  
 Temperature Range - Operating -55°C to +105°C  
 Wire Insulation Diameter 3.30mm  
 Wire Size AWG 18, 20, 22

**Electrical**


Voltage - Maximum 600V

**Material Info**

Old Part Number AA-2140-LIF

**Reference - Drawing Numbers**

Product Specification PS-19902-011, PS-19902-013  
 Sales Drawing SD-19274-001

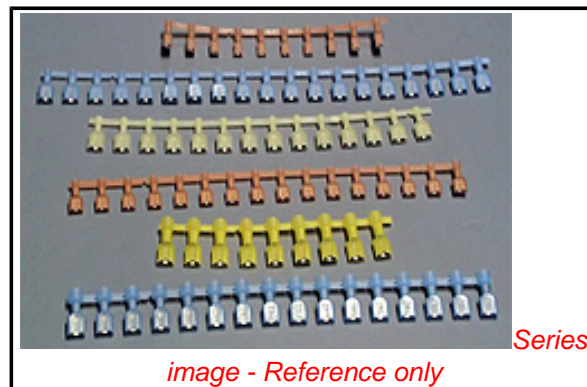

**EU RoHS**

**ELV and RoHS Compliant**  
**REACH SVHC Not Reviewed**  
**Low-Halogen Status Not Reviewed**

**China RoHS**



**Need more information on product environmental compliance?**

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

**Search Parts in this Series**

19274Series

**Application Tooling | FAQ**

*Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.*

**Global**

Description	Product #
Crimp Head for the AT-200™ Pneumatic Hand Tool	<a href="#">0640050200</a>
PremiumGrade™ Hand Crimp Tool	<a href="#">0640010200</a>

This document was generated on 02/24/2015

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**