

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [19276-0002](#)
Status: **Active**
Overview: Quixon™ Terminals
Description: Quixon Quick Disconnect, InsulKrimp™ Style, Female, Fully Insulated Red, 18-22 AWG, Loose

Documents:

[Drawing \(PDF\)](#) [Product Specification PS-19902-013 \(PDF\)](#)
[Product Specification PS-19902-011 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR18689
 UL E79133

General

Product Family Quick Disconnects
 Series [19276](#)
 Comments Low Insertion Force
 Crimp Quality Equipment Yes
 Insulated Fully
 Overview [Quixon™ Terminals](#)
 Product Name InsulKrimp™, Quixon
 Type Quick Disconnect
 UPC 884982565081

Physical

Barrel Type Closed
 Color - Resin Red
 Flammability 94V-2
 Gender Female
 Glow-Wire Compliant No
 Insulation Nylon (PA)
 Lock to Mating Part None
 Material - Metal Brass
 Material - Plating Mating Tin
 Material - Plating Termination Tin
 Net Weight 0.920/g
 Orientation Straight
 Packaging Type Bag
 Tab Thickness 0.41mm
 Tab Width 7.87mm
 Temperature Range - Operating -55°C to +105°C
 Wire Insulation Diameter 3.43mm
 Wire Size AWG 18, 20, 22

Electrical


Voltage - Maximum 600V

Material Info

Old Part Number AA-2201-LIF

Reference - Drawing Numbers

Product Specification PS-19902-011, PS-19902-013
 Sales Drawing SD-19276-001

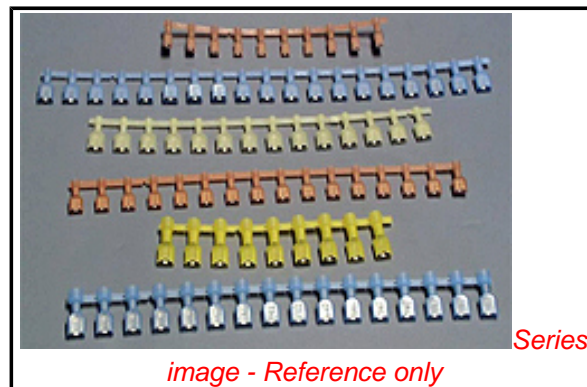

EU RoHS

ELV and RoHS Compliant
REACH SVHC Not Reviewed
Low-Halogen Status Not Reviewed

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

19276Series

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description	Product #
Hand Crimp Tool	0640010400
Crimp Head for the AT-200™ Pneumatic Hand Tool	0640050400

This document was generated on 02/24/2015

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION