

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [39380-0102](#)
Status: **Active**
Overview: Eurostyle™ Terminal Blocks
Description: 6.35mm Pitch Beau™ Eurostyle™ Fixed Mount PCB Terminal Block, Modular, 2 Circuits

Documents:

[3D Model](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Drawing \(PDF\)](#)

General

Product Family	Terminal Blocks
Series	39380
Application	N/A
Component Type	One Piece
Overview	Eurostyle™ Terminal Blocks
Product Name	Eurostyle™ Fixed Mount
Type	Euro Block
UPC	822348022977

Physical

Circuits (Loaded)	2
Color - Resin	Black
Entry Angle	Horizontal
Lock to Mating Part	None
Material - Resin	Nylon
Number of Rows	1
Orientation	Vertical
PC Tail Length	5.20mm
PCB Retention	None
PCB Thickness - Recommended	4.00mm
Panel Mount	No
Pitch - Mating Interface	6.35mm
Pitch - Termination Interface	6.35mm
Polarized to Mating Part	N/A
Shrouded	Fully
Stackable	Yes
Surface Mount Compatible (SMC)	No
Temperature Range - Operating	110°C
Wire Size AWG	10, 12, 14, 16, 18, 20, 22, 24, 26, 28, 30
Wire Size mm²	0.05 - 2.50

Electrical


Current - Maximum per Contact	30A
Voltage - Maximum	300V

Material Info

Old Part Number	380502
-----------------	--------

Reference - Drawing Numbers

Sales Drawing	SD-39380-001
---------------	--------------

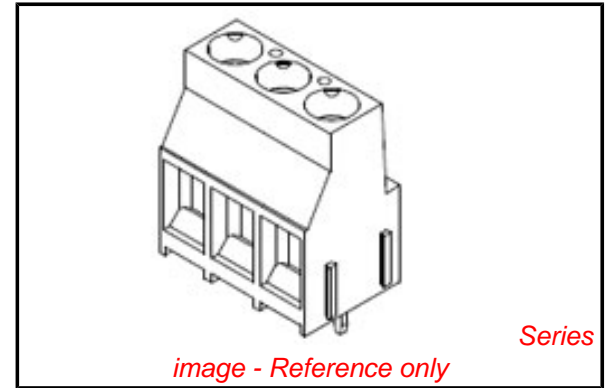

EU RoHS

**ELV and RoHS
Compliant**

REACH SVHC

Not Reviewed

Low-Halogen Status

Low-Halogen

China RoHS



**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

[39380Series](#)