

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

51006-0400

Status:

Active

Description:

2.00mm Pitch Wire-to-Wire Plug Housing, 4 Circuits

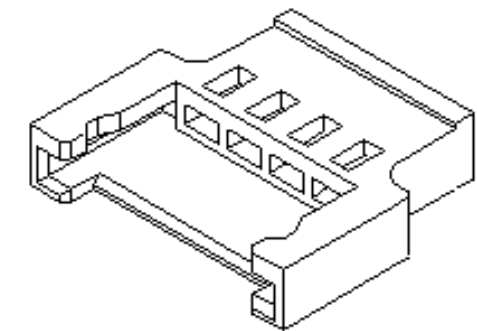


image - Reference only

Series

Documents:

- 3D Model

Packaging Specification SPK-51006-001 (PDF)
- Drawing (PDF)

RoHS Certificate of Compliance (PDF)
- Product Specification PS-51005-001 (PDF)

Agency Certification

CSA	LR19980
UL	E29179

General

Product Family	Crimp Housings
Series	51006
Application	Signal, Wire-to-Wire
MolexKits	Yes
Product Name	N/A
UPC	800753719415

Physical

Circuits (maximum)	4
Color - Resin	Natural
Flammability	94V-0
Gender	Male
Glow-Wire Compliant	No
Lock to Mating Part	None
Material - Resin	Polyester
Net Weight	180.000/mg
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.00mm
Stackable	No
Temperature Range - Operating	-40°C to +105°C

Electrical

Current - Maximum per Contact	2.0A
-------------------------------	------

Material Info

Reference - Drawing Numbers

Packaging Specification	SPK-51006-001
Product Specification	PS-51005-001
Sales Drawing	SD-51006-001

EU RoHS

ELV and RoHS
Compliant
REACH SVHC
Contains SVHC: No
Low-Halogen Status
Not Low-Halogen

China RoHS



Need more information on product
environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of
Compliance, [click here](#)

Please visit the [Contact Us](#) section for any
non-product compliance questions.

Search Parts in this Series
51006Series

Mates With
51005 Female Housing

Use With
50012