

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

79516-1043

Status:

Active

Overview:


Micro-Fit 3.0™ Connectors

Description:

Micro-Fit 3.0™ Overmolded Cable Assembly, 4 Circuit, 3.0m Length

Documents:	
Drawing (PDF)	RoHS Certificate of Compliance (PDF)

General	
Product Family	Cable Assemblies
Series	79516
Assembly Configuration	Dual Ended Connectors
Comments	When using 30 AWG current max per contact is 5A.
Connector to Connector	Micro-Fit 3.0™ Both Ends
Overview	Micro-Fit 3.0™ Connectors
Product Name	Micro-Fit 3.0™
UPC	822348120086
Physical	
Cable Length	3.0m
Circuits (Loaded)	4
Color - Resin	Black
Gender	Female-Female
Lock to Mating Part	Yes
Material - Metal	Phosphor Bronze
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Material - Resin	Polyester, PVC
Net Weight	83.290/g
Packaging Type	Bag
Pitch - Mating Interface	3.00mm
Plating min - Mating	1.016µm
Plating min - Termination	1.016µm
Single Ended	No
Wire Insulation Diameter	N/A
Wire Size AWG	26
Wire/Cable Type	Jacketed
Electrical	
Current - Maximum per Contact	3.0A
Shielded	No
Voltage - Maximum	250V
Material Info	
Reference - Drawing Numbers	
Sales Drawing	SD-79516-002

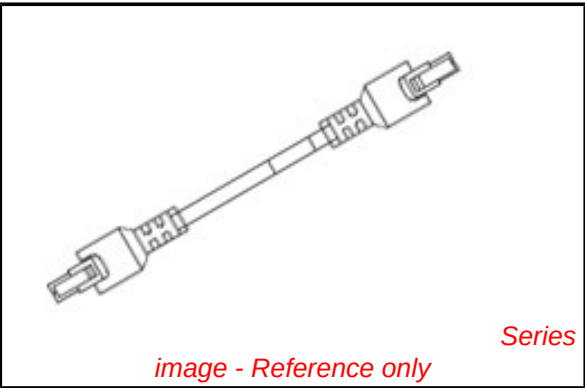

EU RoHS

ELV and RoHS

Compliant

REACH SVHC

Not Reviewed

Low-Halogen Status

Not Reviewed

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com

For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

79516Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION