

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [82-28-3020](#)
Status: **Active**
Description: 1.00mm Pitch Round Conductor Flat Cable - 28 AWG (7 x 36) Stranded, Tinned, 20 Circuits, Reel 30.48m Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR61126
 UL E61522

General

Product Family Cable
 Series [24500](#)
 Crimp Quality Equipment Yes
 Geographic Area Asia
 Product Name Ribbon
 UPC 800754378895

Physical

Cable Length 30.48m
 Circuits (Loaded) 20
 Insulation PVC
 Net Weight 1156.720/g
 Packaging Type Reel
 Pitch - Termination Interface 1.00mm
 Temperature Range - Operating -20°C to +105°C
 Wire Size AWG 28
 Wire/Cable Type (7x36) Stranded, Tinned

Electrical


Current - Maximum per Contact N/A
 Voltage - Maximum 300V

Material Info

Old Part Number 24500-20-100B

Reference - Drawing Numbers

Sales Drawing SD-24500-001

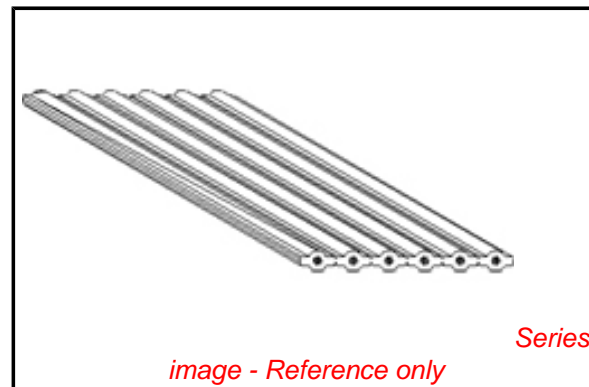

EU RoHS

ELV and RoHS Compliant
REACH SVHC Contains SVHC: No
Low-Halogen Status Not Low-Halogen

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

[24500Series](#)

Use With

[70121](#) MX-50™ Slimline Ribbon Cable.
[90584](#) Picoflex® PF-50 IDT Receptacle

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION