

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [06-02-3103](#)  
**Status:** **Active**  
**Overview:** [Flat Blade](#)  
**Description:** Flat Blade Appliance Motor Switch Crimp Housing, 10 Circuit, 10 Circuits

**Documents:**

[3D Model](#) [RoHS Certificate of Compliance \(PDF\)](#)  
[Drawing \(PDF\)](#)

**Agency Certification**

CSA LR19980  
 UL E29179

**General**

Product Family Crimp Housings  
 Series [6313](#)  
 Application Power, Wire-to-Board  
 Comments Thumb Depress Latch  
 Overview [Flat Blade](#)  
 Product Name Flat Blade  
 UPC 800753825963

**Physical**


Circuits (maximum) 10  
 Color - Resin Natural  
 Flammability 94V-2  
 Gender Female  
 Glow-Wire Compliant No  
 Material - Resin Nylon  
 Net Weight 7.107/g  
 Number of Rows 1  
 Packaging Type Bag  
 Panel Mount No  
 Pitch - Mating Interface 5.59mm  
 Stackable No  
 Temperature Range - Operating -40°C to +75°C

**Material Info**

Old Part Number 6313-1-10

**Reference - Drawing Numbers**

Sales Drawing SD-6313-1-10

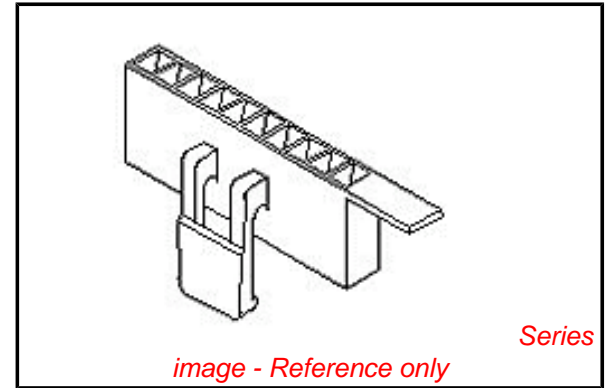

**EU RoHS**

**ELV and RoHS Compliant**  
**REACH SVHC Contains SVHC: No**  
**Low-Halogen Status Low-Halogen**

**China RoHS**



**Need more information on product environmental compliance?**

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

**Search Parts in this Series**

6313Series

**Mates With**

Appliance Motor

**Use With**

1508 Crimp Terminals, 43374