
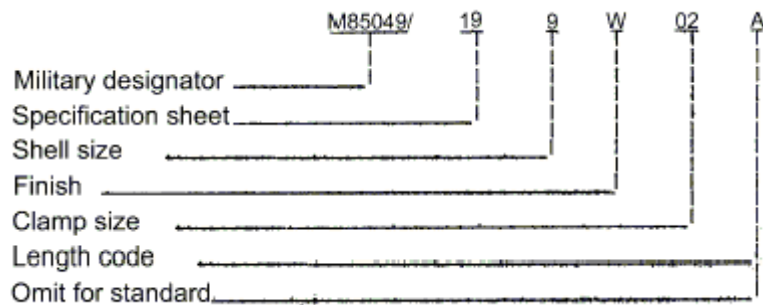


Part Number: M85049/19
Straight EMI/RFI Non-Environmental Backshell

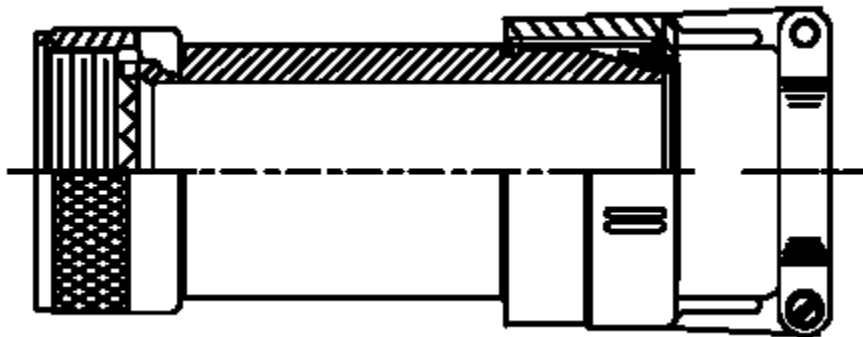

Clamp Size	Cable Diameter Min (in)	Cable Diameter Min (mm)	Cable Diameter Max (in)	Cable Diameter Max (mm)
01	.062	(1.6)	.125	(3.2)
02	.125	(3.2)	.250	(6.4)
03	.250	(6.4)	.375	(9.5)
04	.312	(7.9)	.500	(12.7)
05	.437	(11.1)	.625	(15.9)
06	.562	(14.3)	.750	(19.1)
07	.687	(17.4)	.875	(22.2)
08	.812	(20.6)	1.000	(25.4)
09	.937	(23.8)	1.125	(28.6)
10	1.062	(27.0)	1.250	(31.8)

Finish

N = Electroless Nickel

X = Aluminum, Nickel Fluorocarbon Polymer

W = 1,000 Hr. Cadmium Olive Drab

Z = Aluminum, Zinc-Nickel, Black over Electroless Nickel

Joslyn Sunbank Company LLC.
1740 Commerce Way - Paso Robles, California 93446
805238-2840 fax805238-0241
www.sunbankcorp.com