




Thermocouple Extension Cable PTFE Insulated Flat Pair

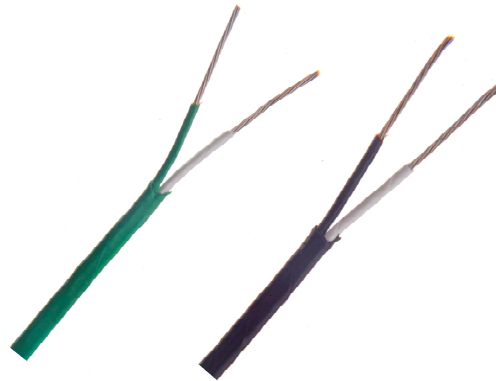

- ◆ PTFE insulated flat pair cable
- ◆ Single pair of PTFE insulated conductors, laid flat with PTFE jacket
- ◆ Good mechanical strength and flexibility, resistant to oils, acids and other adverse fluids
- ◆ Suitable for steam & pressure applications, autoclaves, sterilisers etc.
- ◆ Thermocouple types K & T with 7/0.2mm stranded conductors
- ◆ 25 metre reel lengths
- ◆ Tolerance Class 1 for optimum accuracy
- ◆ Insulation rating -75°C to 260°C
- ◆ Colour code (cores & jacket) to IEC-584-3

T/C Type	Conductors	mm ²	Cores	Jacket	Reel Length	Manufacturers Part No.	Farnell Order Code
K	7/0.2mm	0.219	+Green/-White	Green	25m	WK-302/25M	708-5904
T	7/0.2mm	0.219	+Brown/-White	Brown	25m	WT-046/25M	708-5916

About Labfacility

Formed in 1971, Labfacility specialize in the field of Temperature and Process Measurement.

We are the largest UK manufacturer of both temperature sensors and thermocouple connectors

Quality & Service

Quality and Service are key elements in the continued growth of Labfacility.

Technical support is always freely available from our experienced technical sales teams and the company has ISO9001 accreditation.

Contact Details

Email
sales@labfacility.com

Website
www.labfacility.com