



Glassfibre Exposed Welded Tip Thermocouples with Plug

About Labfacility

Formed in 1971, Labfacility specialize in the field of Temperature and Process Measurement.

We are the largest UK manufacturer of both temperature sensors and thermocouple connectors.


Quality & Service

Quality and Service are key elements in the continued growth of Labfacility.

Technical support is always freely available from our experienced technical sales teams and the company has ISO9001 accreditation.



Types K with 're-wireable' miniature flat pin plug

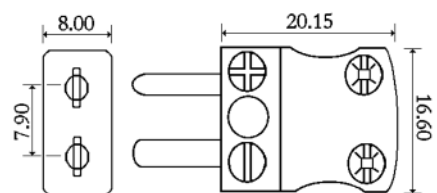

Miniature Plug

- ◆ Thermocouple type K
- ◆ Fast response, welded exposed junction
- ◆ 1 or 2 metre long glassfibre insulated flat pair cable
- ◆ Good temperature resistance (not suitable in fluids)
- ◆ 1/0.315mm conductors
- ◆ 'Re-Wireable' miniature flat pin plug
- ◆ Temperature range -50°C to +350°C (short periods up to 400°C)
- ◆ Tolerance to ANSI MC96.1 Class 2
- ◆ Colour code to ANSI MC96.1
- ◆ Ideal for test & development applications

T/C Type	Length	+Positive tail wire	-Negative tail wire	Manufacturing Part Number	Farnell order code
'K'	1 metres	Yellow	Red	Z3-K-1.0-1/0.315-MP-ANSI	244-3724
'K'	2 metres	Yellow	Red	Z3-K-2.0-1/0.315-MP-ANSI	244-3725

Contact Details

Email
sales@labfacility.com

Website
www.labfacility.com