




SERIES 690W

WATERPROOF USB & HDMI

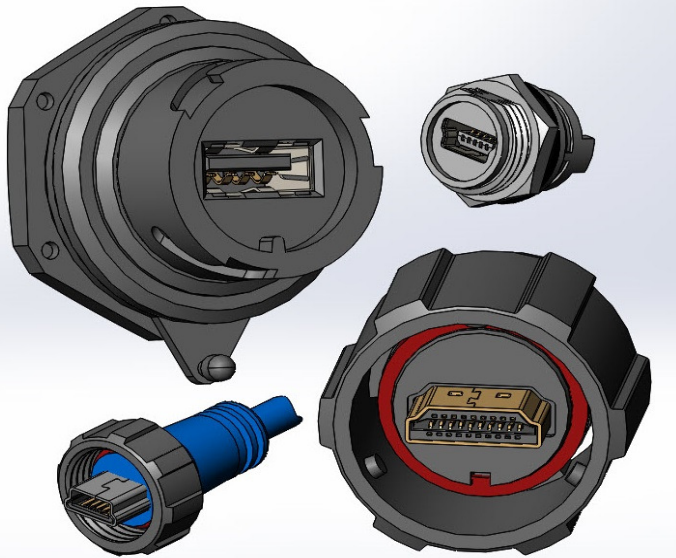

FEATURES:

- E-SEAL Waterproof Connectors
 - Standard USB TypeA
 - Micro USB
 - Mini USB Type B
 - HDMI Type A
- Material: Thermoplastic, UL 94V-0 Rated, Black color
- Shell: Steel, Nickel Plated
- O-Ring: Silicone
- Contact Material: Phosphor Bronze, Gold Plated
- Compatible with all Windows versions
- 1.2Mbps or 480Mbps communication speed
- Complies with USB1.0 (USB2.0 upon request)
- Compatible with asynchronous and isochronous data transfer methods
- Silicone rubber seals
- Secure latching system for safe mating under severe vibration or shock conditions


SPECIFICATIONS:

- Rated Current: 1A
- Contact Resistance: 50 mOhm Max
- Insulation Resistance: 100 MOhm Min
- Temperature Rating: -25°C ~ +85°C
- Degree of Protection: IP67 as per IEC60529



Example Part Number:

690-W04-260-012

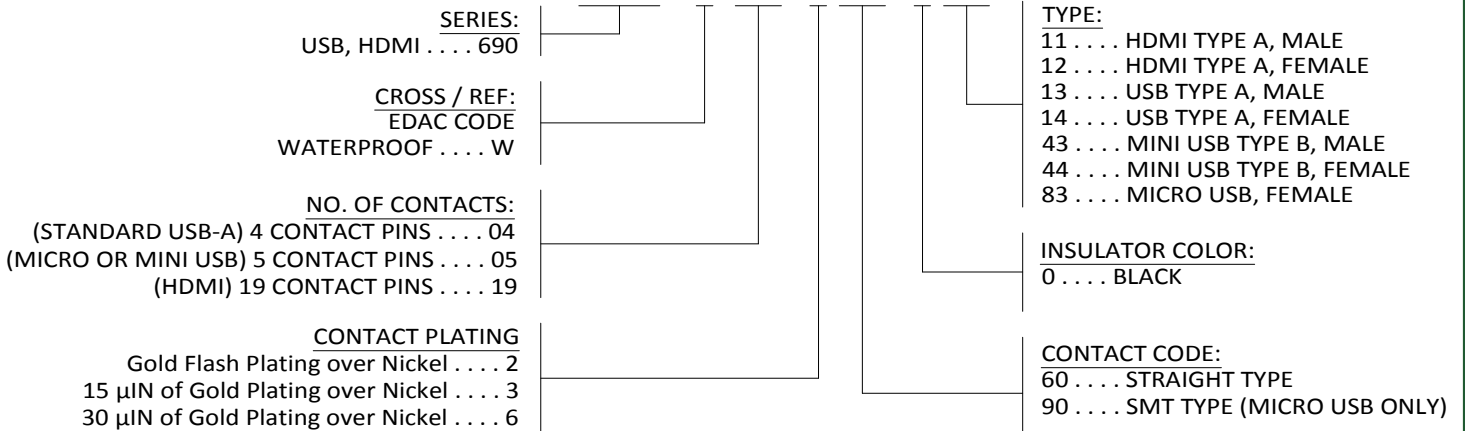

NOTE:

MICRO USB IS ONLY AVAILABLE IN SMT TYPE