



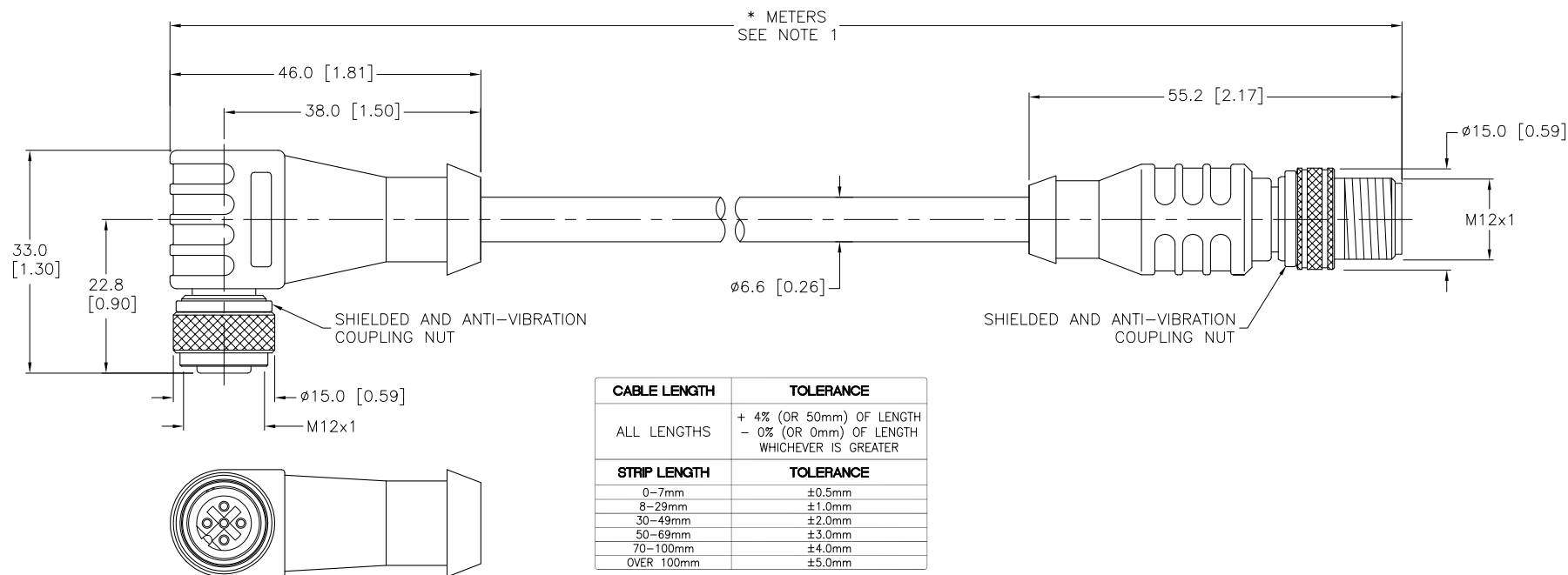


FEMALE END VIEW		MALE END VIEW		SPECIFICATIONS																									
 <p>1 = BROWN 2 = WHITE 3 = BLUE 4 = BLACK 5 = GRAY</p> 		 <p>1 = BROWN 2 = WHITE 3 = BLUE 4 = BLACK 5 = GRAY</p> 		<table><tr><td>CONTACT CARRIER MATERIAL</td><td>NYLON or TPU</td></tr><tr><td>MOLDED HEAD MATERIAL/COLOR</td><td>TPU/YELLOW</td></tr><tr><td>CONTACT MATERIAL/PLATING</td><td>BRASS/GOLD</td></tr><tr><td>COUPLING NUT MATERIAL/PLATING</td><td>BRASS/NICKEL</td></tr><tr><td>RATED CURRENT [A]</td><td>4.0 A</td></tr><tr><td>RATED VOLTAGE [V]</td><td>250 V</td></tr><tr><td>OUTER CABLE JACKET MATERIAL/COLOR</td><td>PVC/GRAY</td></tr><tr><td>CONDUCTOR INSULATION MATERIAL</td><td>PVC</td></tr><tr><td>NUMBER OF CONDUCTORS [AWG]</td><td>5x22 AWG</td></tr><tr><td>DRAIN/SHIELD</td><td>24 AWG DRAIN/FOIL AND BRAIDED SHIELD</td></tr><tr><td>TEMPERATURE RANGE</td><td>-40°C to +105°C (-40°F to +221°F)</td></tr><tr><td>PROTECTION CLASS</td><td>MEETS IEC IP67</td></tr></table>		CONTACT CARRIER MATERIAL	NYLON or TPU	MOLDED HEAD MATERIAL/COLOR	TPU/YELLOW	CONTACT MATERIAL/PLATING	BRASS/GOLD	COUPLING NUT MATERIAL/PLATING	BRASS/NICKEL	RATED CURRENT [A]	4.0 A	RATED VOLTAGE [V]	250 V	OUTER CABLE JACKET MATERIAL/COLOR	PVC/GRAY	CONDUCTOR INSULATION MATERIAL	PVC	NUMBER OF CONDUCTORS [AWG]	5x22 AWG	DRAIN/SHIELD	24 AWG DRAIN/FOIL AND BRAIDED SHIELD	TEMPERATURE RANGE	-40°C to +105°C (-40°F to +221°F)	PROTECTION CLASS	MEETS IEC IP67
CONTACT CARRIER MATERIAL	NYLON or TPU																												
MOLDED HEAD MATERIAL/COLOR	TPU/YELLOW																												
CONTACT MATERIAL/PLATING	BRASS/GOLD																												
COUPLING NUT MATERIAL/PLATING	BRASS/NICKEL																												
RATED CURRENT [A]	4.0 A																												
RATED VOLTAGE [V]	250 V																												
OUTER CABLE JACKET MATERIAL/COLOR	PVC/GRAY																												
CONDUCTOR INSULATION MATERIAL	PVC																												
NUMBER OF CONDUCTORS [AWG]	5x22 AWG																												
DRAIN/SHIELD	24 AWG DRAIN/FOIL AND BRAIDED SHIELD																												
TEMPERATURE RANGE	-40°C to +105°C (-40°F to +221°F)																												
PROTECTION CLASS	MEETS IEC IP67																												

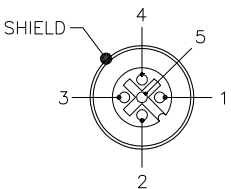

SOURCE DRAWING - FOR REFERENCE ONLY

NOTES:

1. "*" INDICATES CABLE LENGTH IN METERS. CONTACT TURCK TO ORDER SPECIFIC LENGTHS.
2. COUPLING NUTS ARE CONNECTED TO SHIELD.

E	UPDATE CABLE	CK	06/16/11	35087	SEE SPECIFICATIONS	CONTACT TURCK FOR MORE INFORMATION	UNIT OF MEASUREMENT MILLIMETER [INCH]	DATE 05/08/01 SCALE 1=1	DESCRIPTION WKS 4.5T-*—RSS 4.5T	IDENTIFICATION NO.	REV E
REV	DESCRIPTION	BY	DATE	ECO NO.							

DO NOT SCALE THIS DRAWING

FILE: 777000246

SHEET 1 OF 1