


**AMP AMPLIMITE®
D-SUBMINIATURE
CONNECTOR CABLE
ASSEMBLIES**



Authorized Distributor

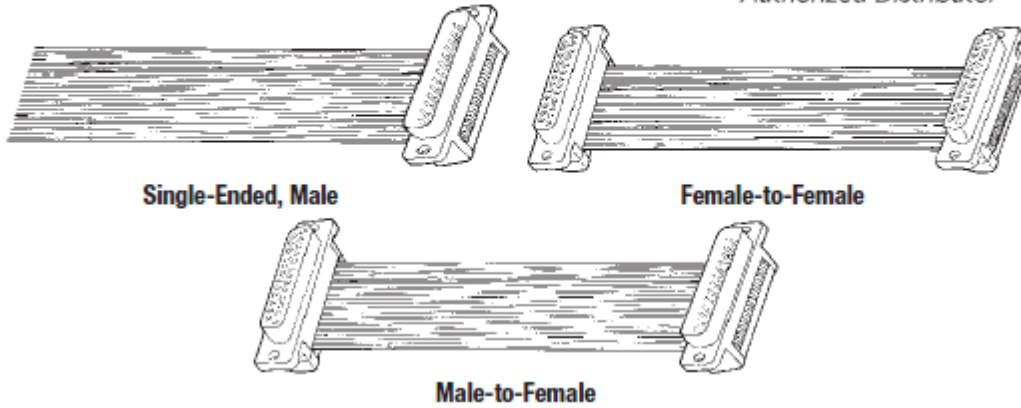

- Black Thermoplastic Housing and Cover, Rated UL94V-0
- Phosphor Bronze Contacts
- Available with D-subminiature plugs and receptacles (RS-232)
- Single-ended or double-ended configurations
- Flat ribbon cable has 28 AWG tinned copper, 7/36 stranded conductors on 0.050" (1.27) centers
- 6" length
- UL recognized
- CSA certified

Mfg. Part No.	No. of Positions
D-SUBMINIATURE PLUG, SINGLE-ENDED – MALE	
NE2125-06-ROHS	25
NE2137-06-ROHS	37
D-SUBMINIATURE RECEPTACLE, SINGLE-ENDED – FEMALE	
NE2215-06-ROHS	15
D-SUBMINIATURE PLUG-TO-PLUG – MALE-TO-MALE	
NE2315-06-ROHS	15
NE2337-06-ROHS	37
D-SUBMINIATURE RECEPTACLE-TO-RECEPTACLE – FEMALE-TO-FEMALE	
NE2425-06-ROHS	25
NE2437-06-ROHS	37
D-SUBMINIATURE PLUG-TO-RECEPTACLE – MALE-TO-FEMALE	
NE2509-06-ROHS	9
NE2515-06-ROHS	15
NE2537-06-ROHS	37