

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [19127-0009](#)
Status: **Active**
Overview: [Solderless Terminals](#)
Description: Avikrimp™ Flanged Spade Tongue Terminal for 22-18 AWG Wire, Stud Size 6 (M3.5), Mylar Tape Carrier

Documents:
[Drawing \(PDF\)](#) [Product Specification PS-19902-015 \(PDF\)](#)
[Product Specification PS-19902-011 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR18689
UL E32244

General

Product Family Ring and Spade Terminals
Series [19127](#)
Crimp Quality Equipment Yes
Mil-Spec N/A
Overview [Solderless Terminals](#)
Product Name Avikrimp™
Type Spade
UPC 800753098909

Physical


Barrel Type Closed
Flammability 94V-2
Insulation Nylon (PA)
Material - Plating Mating Tin
Net Weight 0.801/g
Packaging Type Adhesive Tape on Reel
Stud Size 6 (M3.5)
Wire Insulation Diameter 3.56mm max.
Wire Size AWG 18, 20, 22
Wire Size mm² 0.25 - 1.50

Material Info

Old Part Number AA-815-06T

Reference - Drawing Numbers

Product Specification PS-19902-011, PS-19902-015
Sales Drawing SD-19127-003

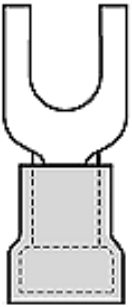

Series

image - Reference only

EU RoHS
ELV and RoHS
Compliant
REACH SVHC
Contains SVHC: No
Low-Halogen Status
Not Low-Halogen

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series
[19127Series](#)

Application Tooling | FAQ
Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global	
Description	Product #
ATP Crimp Dies for the Tape Crimp Module and ATP-101 & 301 Press	0192880023