

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [19003-0042](#)
Status: **Active**
Overview: [Standard Quick-Disconnect Terminals](#)
Description: InsulKrimp™ Quick Disconnect, Female, for 14-16 (2.00-1.30mm²), Mylar Tape, Tab 6.35 x 0.81mm

Documents:
[3D Model](#)
[Drawing \(PDF\)](#)
[Product Specification PS-19902-008 \(PDF\)](#)
[Product Specification PS-19902-011 \(PDF\)](#)
[Product Specification PS-19902-015 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR18689
UL E79133

General

Product Family Quick Disconnects
Series [19003](#)
Comments Funnel Entry
Crimp Quality Equipment Yes
Insulated Fully
Overview [Standard Quick-Disconnect Terminals](#)
Product Name InsulKrimp™
Type Quick Disconnect
UPC 800753029095

Physical


Barrel Type Closed
Color - Resin Blue
Flammability 94V-2
Gender Female
Glow-Wire Compliant Yes
Insulation Nylon (PA)
Lock to Mating Part None
Material - Metal Brass
Material - Plating Mating Tin
Material - Plating Termination Tin
Material - Resin Nylon
Net Weight 0.962/g
Orientation Straight
Packaging Type Adhesive Tape on Reel
Plating min - Mating 4.064µm
Plating min - Termination 4.064µm
Polarized to Mating Part No
Tab Thickness 0.81mm
Tab Width 6.35mm
Temperature Range - Operating -65°C to +105°C
Termination Interface: Style Crimp or Compression
Wire Insulation Diameter 3.68mm max.
Wire Size AWG 14, 16
Wire Size mm² 1.30 - 2.00

Electrical

Voltage - Maximum 600V

Material Info

Old Part Number BB-2206T

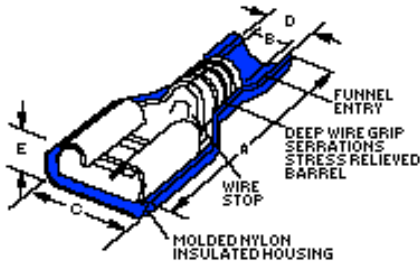

Series

image - Reference only

EU RoHS
ELV and RoHS
Compliant
REACH SVHC
Contains SVHC: No
Low-Halogen Status
Low-Halogen

China RoHS



Need more information on product environmental compliance?
Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series
[19003Series](#)

Application Tooling | FAQ
Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.
Global

Description	Product #
Mini-Mac™ Applicator	0638854200
ATP Crimp Dies for the Tape Crimp Module and ATP-101 & 301 Press	0192880105

Reference - Drawing Numbers

Product Specification
Sales Drawing

PS-19902-008, PS-19902-011, PS-19902-015
SD-19003-005

This document was generated on 04/02/2015

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION