

AUDIO/VIDEO



AUDIO/VIDEO CABLE (Cont.)

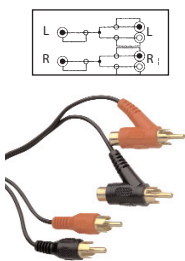


Fig. 1

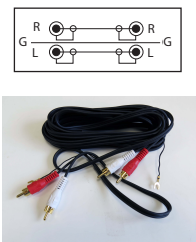


Fig. 2

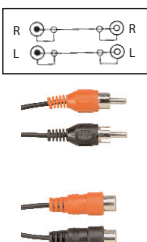


Fig. 3

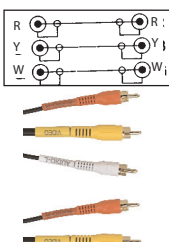


Fig. 4



Fig. 5

Audio/Video Cable

Retail Part No.	Bulk Part No.	Figure Number	Description	Cable Length
30-1827		1	Shielded Pistol Type Dual Plugs with RCA Jack Adapter to Dual RCA Plugs	2m ('6')
30-1828		1	Shielded Pistol Type Dual Plugs with RCA Jack Adapter to Dual RCA Plugs	3.75m ('12')
30-413		2	Shielded Car Stereo-Dual RCA to Dual RCA with Grounding Wire at Both Ends	5m ('16')
30-410		3	Dual Shielded RCA Plugs to Dual RCA Jacks	1m ('3')
30-411		3	Dual Shielded RCA Plugs to Dual RCA Jacks	2m ('6')
30-1537		4	Interconnect Cable Triple RCA Plug RWY-Gold	2m ('6')
30-1537-25		4	Interconnect Cable Triple RCA Plug RWY-Gold	2m ('6')
SD-1538		4	Dubbing Cable Triple RCA Plug RWY-Gold-Stereo	3.75m ('12')
32-3236		5	RG-59 Dual Phono (RCA-Type) Plug to Dual Phono (RCA-Type) Plug-Gold	2m ('6')

AUDIO CABLE

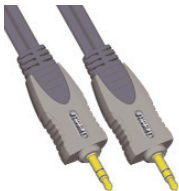


Fig. 6

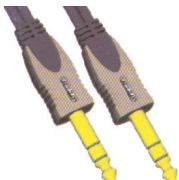


Fig. 7



Fig. 8



Fig. 9



Fig. 10

Audio Cables

Retail Part No.	Bulk Part No.	Figure Number	Description	Length (Meters)	Ferrite Bead
65-1713-1M		6	Stereo Cable 3.5mm Phone Plug to 3.5mm Phone Plug	1	No
65-1719-1M		7	Stereo Cable 1/4" Phone Plug to 1/4" Phone Plug	1	No
65-1720-1M		8	Phone Plug 3.5mm Quad Plug to 3.5mm Quad Jack	1	No
65-1723-1M		9	Phone Plug 3.5mm Quad Plug to 3xRCA Plugs RWY	1	No
65-1726-1M		10	Phone Plug Rt. Angle 3.5mm Quad Plug to 3xRCA Plugs RWY	1	No

For the latest information—www.gcelectronics.com

All quantities are single; BU's are packages of 10 Unless otherwise noted.

PHONE PLUG CABLES

 


Fig. 1

 


Fig. 2


 


Fig. 3

 

~~Fig. 4~~

 


Fig. 5

 


Fig. 6

 


Fig. 7

 


Fig. 8



Fig. 9

 


Fig. 10

 


Fig. 11



Fig. 12

 


Fig. 13

 


Fig. 14



Fig. 15

 


Fig. 16

 


Fig. 17

Phone Plug Cables

Retail Part No.	Bulk Part No.	Figure Number	Description	Cable Length
30-401		1	Shielded Single RCA Plug to 3.5mm Mini Phone Plug	1m ('3')
30-403		1	Shielded Single RCA Plug to 3.5mm Mini Phone Plug	2m ('6')
30-1812		2	Shielded Dual RCA Plug to 3.5mm Stereo Mini Plug	2m ('6')
30-444		3	Shielded Single RCA Plug to 1/4" Phone Plug	2m ('6')
30-1830		4	2 Conductor 2.5mm Subminiature Plug to 2.5mm Subminiature Jack	6m ('20')
30-415		5	2 Conductor 3.5mm Mini Phone Plug to Stripped end Cable	2m ('6')
30-1808		6	2 Conductor 3.5mm Mini Phone Plug to 3.5mm Phone Plug	1m ('3')
30-1809		6	2 Conductor 3.5mm Mini Phone Plug to 3.5mm Phone Plug	2m ('6')
30-1806		7	2 Conductor 3.5mm Mini Phone Plug to 3.5mm Phone Jack	2m ('6')
30-1807		7	2 Conductor 3.5mm Mini Phone Plug to 3.5mm Phone Jack	3.75m ('12')
30-431		8	2 Conductor 3.5mm Mini Phone Plug to 1/4" Phone Plug	2m ('6')
30-434		9	3 Conductor 3.5mm Mini Phone Plug to 1/4" Phone Plug	2m ('6')
30-443		10	2 Conductor 1/4" Phone Plug to 1/4" Phone Plug	2m ('6')
30-556		11	Coiled 3 Conductor 1/4" Phone Plug to Right Angle 1/4" Phone Plug	6m ('20')
30-1821		12	3 Conductor Stereo 3.5mm Mini Phone Plug to Stereo 3.5mm Mini Phone Plug	2m ('6')
30-1811		13	3 Conductor Stereo 3.5mm Mini Phone Plug to Stereo 3.5mm Mini Phone Jack	3m ('10')
30-1824		14	3 Conductor Stereo 1/4" Phone Plug to Stereo 1/4" Phone Jack	6m ('20')
30-1825		15	Coiled 3 Conductor Stereo 1/4" Phone Plug to Stereo 1/4" Phone Jack	7.6m ('25')
30-1697		16	Microphone Cable Low Noise	5m ('16')
30-1695		17	Microphone Cable	6m ('20')

STEREO HEADPHONES



Fig. 1



Fig. 2



Fig. 3



Fig. 4



~~Fig. 5~~

Stereo Headphones

Retail Part No.	Figure No.	Description	Features
61-533	1	Lightweight Stereo Headphones	27mm Mylar Speaker; 32 Ohms; 20-20,000Hz; 100dB S.P.L.@1kHz+2%; 4ft. Cord Length
61-548	2	Digital Stereo Headphones	27mm Mylar Speaker; 32 Ohms; 20-18,000Hz; 101dB S.P.L.@1kHz+2%; 4ft. Cord Length
61-555	3	Stereo Headphones	27mm Mylar Speaker; 32 Ohms; 20-20,000Hz; 101dB S.P.L.@1kHz+2%; 4ft. Cord Length
90-502	4	Dynamic Stereo Headphones	20-18,000Hz; 32 Ohms; Max Input 100 mW
30-1831	5	Headphones Extension Cable	25 ft. Coiled Cable; 3.5mm Stereo Jack/1/4" Stereo Phone Plug

ACCESSORIES



Fig. 6



Fig. 7



Fig. 8



Fig. 9



Fig. 10



Fig. 11



Fig. 12



Fig. 13



Fig. 14

Accessories

Retail Part No.	Bulk Part No.	Figure Number	Description	Features
30-3152		6	Cigarette Lighter Plug & 2 Terminals	For Operating CB'S,Trouble Lights, Etc.
36-902		7	Cigarette Lighter Plug-Fused	For Operating CB'S, Trouble Lights, Etc. 2 amp Fuse.
30-3155		8	DC Power Cord	6 ft. Cord; Right Angle 2.1mm Power Supply
30-3151		9	Dual Cigarette Lighter "Y" Adapter	12" Y Cord for Cell Phone, Radar Detector, Etc.
30-3153		10	Triple Cigarette Lighter Socket Adapter	3 ft. Cord for Cell Phones, Radar Detector, Etc.
30-3124		11	DC Adapter 3.6, 7.5 or 9 Volts	Transistor Regulates Circuit; Assures Constant Voltage
30-3162		12	USB Charger 2 Port AC/DC	2 in 1 Inputs, 12V DC and 120VAC
30-3158		13	Cigarette Plug Switch with Cord	8 Ft. Cord, Switch, 5A, Stripped Ends
30-6019		14	USB Charger 4 Port 120V	5VDC 1 AMP Output, Flip-Up Plug

AUDIO CONNECTORS



Fig. 1



Fig. 2



Fig. 3



Fig. 4



Fig. 5

PowerFlex™ Audio Connectors

Retail Part No.	Bulk Part No.	Figure Number	Description	Use with GC Wire Part No.	Quantity per Retail Pack
30-1200		1	Gold Compression (Solderless) Spade Lugs	14-210-9H_3, 30-581*	2; 1-Red, 1-Black
30-1204		2	Gold Crimp or Solder Flexible Pin Lugs	14-210-9H_3, 30-581*	4; 2-Red, 2-Black
30-1205		3	Gold Compression (Solderless) Pin Plugs	14-210-9H_3, 30-581*	2
30-1208		4	Gold Crimp or Solder Banana Plugs	14-210-9H_3, 30-581*	2; 1-Red, 1-Black
30-1210		5	Gold Compression (Solderless) Banana Plugs	14-210-9H_3, 30-581*	2

*Can also be used with any other hook-up wire on pages 422 - 423.



Fig. 6



Fig. 7



Fig. 8



Fig. 9



Fig. 10



Fig. 11



Fig. 12

RCA Phono Plugs

Retail Part No.	Bulk Part No.	Bulk 100 Part No.	Figure No.	Description	Use with GC Wire Part No.	Quantity Per Retail Pack
	33-131-BU		6	Black Plastic, Combination Clamp & Solder Terminals	14-1918-1H89	
	33-132-BU		6	Red Plastic, Combination Clamp & Solder Terminals	14-1918-1H89	
	33-133-BU		6	Metal, Combination Clamp & Solder Terminals	14-1918-1H89	
30-533			7	Right Angle, Solderless Terminals,	14-1924-9H81	2; 1-Red, 1-Black
30-534	30-534-BU		8	Heavy Duty, Solder Terminals	14-1918-1H89	2
30-534-3			8	Heavy Duty, Solder Terminals-Gold	14-1918-1H89	2
30-1230			9	Platinum, Gold Phono Plugs, Solder Connection	14-1918-1H89	2
30-1231			10	Black, Gold Phono Plugs, Solder Connection	14-1918-1H89	2
30-1232			11	Red, Gold Phono Plugs, Solder Connection	14-1918-1H89	2
	32-451-BU	32-451-100	12	Compression Connector, 1-Piece-Red Banded for RG-59	14-1924-9H81	
32-453	32-453-BU	32-453-100	12	Compression Connector, 1 Piece Yellow Banded for RG-6	14-1918-1H89	1
32-454-BU	32-454-100	32-454-100	12	Compression Connector, 1 Piece Blue Banded for RG-6 Quad.	14-1918-1H81	



Fig. 13



Fig. 14



Fig. 15



Fig. 16



Fig. 17



Fig. 18

RCA Phono Jacks

Retail Part No.	Bulk Part No.	N.S.N. Number	Figure No.	Description	Use with GC Wire Part No.	Quantity Per Retail Pack
30-528			13	Chassis Mounting, Open Circuit, Solder Lugs	14-1918 or 14-1924	2
30-528-3			14	Chassis Mounting, Gold	14-1918 or 14-1924	1
	33-134-BU	5935-00-023-5360	15	Cord Mounting Metal, Combination Clamp/Style	14-1918 or 14-1924	
	33-135-BU		16	Single Hole Panel Phono Jack, 9/32" Hole	14-1918 or 14-1924	
30-536			17	Cord Mounting, Open Circuit, Solder Terminals	14-1918 or 14-1924	2
30-537			18	Dual Chassis Mounting, Open Circuit, Solder Type	14-1918 or 14-1924	1

AUDIO/VIDEO



ACCESSORIES (Cont.)



Fig. 1



Fig. 2



Fig. 3



Fig. 4




Fig. 5



Fig. 6



~~Closed
Fig. 7~~

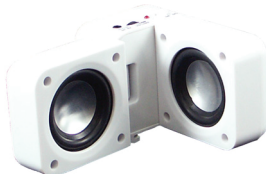

~~Half Opened
Fig. 7~~



~~Shown with iPod
(iPod not included)
Fig. 7~~

Retail Part No.	Figure No.	Description	Features
30-6012	1	500mA Universal AC/DC Adapter 12w	3.5mm Male, 2.0mm x 5.0mm, 2.1mm x 5.5mm, 2.5mm x 5.5mm, 1.35mm x 3.5mm, 1.5mm x 5.5mm Output: 3, 4.5, 6, 7.5, 9, 12 Vdc
61-6012	1	500mA Universal AC/DC Adapter 12w	3.5mm Male, 2.0mm x 5.0mm, 2.1mm x 5.5mm, 2.5mm x 5.5mm, 1.35mm x 3.5mm, 1.5mm x 5.5mm Output: 3, 4.5, 6, 7.5, 9, 12 Vdc
61-6014	2	800mA Universal AC/DC Adapter 16w	3.5mm Male, 2.0mm x 5.0mm, 2.1mm x 5.5mm, 2.5mm x 5.5mm, 1.35mm x 3.5mm, 1.5mm x 5.5mm Output: 3, 4.5, 6, 7.5, 9, 12 Vdc
30-160	3	Pillow Speaker	6 Ft. Cord with 3.5mm Phone Plug. 8 Ohm Impedence
30-5300	4	Miniature Earphones	Miniature (3.5mm) Plug; 3 Ft. Cord; Low Impedence
30-5302	4	Miniature Earphones	Miniature (3.5mm) Plug; 3 Ft. Cord; High Impedence
30-5304	4	Miniature Earphones	Subminiature (2.5mm) Plug; 3 Ft. Cord; Low Impedence
30-041	5	Foot Switch	Maximum Rating: Vdc 6 Ft. Cable with Subminiature (2.5mm) Plug
30-467	6	Cassette Power Cord	SPT-1, 18 Gauge, 2 Conductor Cord, 6 Ft. Replacement; Non-Polarized
64-8864	7	Magnetically Shielded Multimedia Speaker Cube	USB or Battery powered, compact fold-up design, gold stereo 1/8" (3.5mm) plug. Works with all iPod players, MP3 players, CD players, Cassette players and other audio devices that feature a 1/8" (3.5mm) jack

AUDIO "Y" ADAPTERS (Cont.)



Fig. 1

Fig. 2



Fig. 3



Fig. 4



Fig. 5



Fig. 6



Fig. 7



Fig. 8

Miniature Plug & Jack Combinations

Retail Part No.	Bulk Part No.	Figure Number	Description
30-1558		1	Miniature(3.5mm) Mono Phone Plug to 2 Miniature(3.5mm) Phone Jacks
30-1559		2	Miniature(3.5mm) Stereo Phone Plug to 2 Miniature(3.5mm) Stereo Phone Jacks
30-1565		3	Miniature(3.5mm) Stereo Phone Plug to 2 RCA Jacks (Basic)

"Y" Adapters

Retail Part No.	Bulk Part No.	Figure Number	Description
30-500		4	Standard(1/4") Mono Phone Plug to 2 Phono Jacks
30-504		5	RCA Phono Plug to 2 Phono Jacks

Auto Antenna "Y" Connector

Retail Part No.	Bulk Part No.	Figure Number	Description
30-3081		6	Allows Hook-up of an Add. AM, FM, AM/FM, CB Radio to Car Radio Antenna

S-VHS "Y" Adapters

Retail Part No.	Bulk Part No.	Figure Number	Description
65-4401		7	1 S-VHS Plug to 2 S-VHS Jacks
65-4402		8	2 S-VHS Plugs to 1 S-VHS Jack



Fig. 9



Fig. 10



Fig. 11



Fig. 12



Fig. 13



Fig. 14



Fig. 15

Subminiature(2.5mm) Phone Plugs

30-604 Miniature 3.5mm 4 Conductor Plug

Retail Part No.	Bulk Part No.	Figure Number	Description	Quantity Per Retail Pack
	33-091-BU	9	Subminiature Mono Phone Plug, Solder Lug	
30-519		10	Subminiature Stereo Phone Plug	2

Miniature(3.5mm) Mono Phone Plugs

Retail Part No.	Bulk Part No.	N.S.N. Number	Figure No.	Description	Quantity Per Retail Pack
	33-092-BU		11	Miniature(3.5mm) Mono Phone Plug-Brass, Clamp-Solder Terminals	
30-498-6			11	Miniature(3.5mm) Phone Plug-Shielded Metal Handle, Solder Terminals	1
30-498-2			12	Miniature(3.5mm) Phone Plug-Black Plastic Handle, Solder Terminals	1
30-498-3			13	Miniature(3.5mm) Phone Plug-Gold, Solder Terminals	1
	33-093-BU		13	Miniature(3.5mm) Mono Phone Plug-Black, Clamp-Solder Terminals	

Miniature(3.5mm) Stereo Phone Plugs

30-604

3.5mm 4 Cond. Phone Plug Blk

Retail Part No.	Bulk Part No.	Figure Number	Description	Quantity Per Retail Pack
30-572	30-572-BU	14	Miniature(3.5mm) Stereo-Black Plastic Handle	1
30-572-3		15	Miniature(3.5mm) Stereo-Black Plastic Handle, Gold	1

PHONE PLUGS (Cont.)



Fig. 1

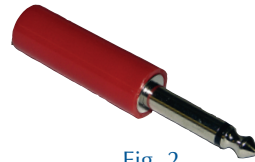


Fig. 2



Fig. 3



Fig. 4



Fig. 6



Fig. 8



Fig. 9

Standard (1/4") Mono Phone Plugs

Retail Part No.	Bulk Part No.	Figure Number	Description	Use with GC Wire Part No.
30-483	33-087-BU	1	Phone Plug-Molded Black Plastic, Solder Terminals	14-1918 or 14-1924
30-483-1		2	Red Plastic Handle, Solder Terminals	14-1918 or 14-1924
30-484-1		2	Red Plastic Handle, Screw Terminals	14-1918 or 14-1924
30-483-6	33-088-BU	3	Shielded Metal Handle, Solder Terminals	14-1918 or 14-1924
30-484-6	33-086-BU	3	Shielded Metal Handle, Screw Terminals	14-1918 or 14-1924
30-487		4	Shielded (1/4") Metal Handle, Right Angle Type, Screw Terminals	14-1918 or 14-1924

Standard (1/4") Stereo Phone Plugs

Retail Part No.	Bulk Part No.	Figure Number	Description	Use with GC Wire Part No.
30-489	33-089-BU	6	Black, Combination Clamp/Solder Lug	14-1918 or 14-1924
30-489-6	33-090-BU	8	Shielded Metal Handle, Solder Terminals	14-1918 or 14-1924
30-490		9	Shielded Metal Handle, Screw Terminals	14-1918 or 14-1924



Fig. 12



Fig. 13

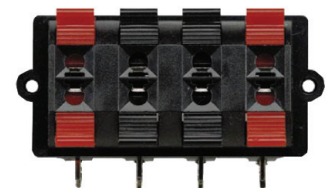


Fig. 14

2 Position Pushbutton Terminal Board

Retail Part No.	Bulk Part No.	Figure Number	Description	Use with GC Wire Part No.
33-1402		12	Red/Black Posts Mounts in 2" Holes, 1-1/4"D, 1-3/4" Mounting Centers	14-218-2E_3

4 Position Pushbutton Terminal Board

Retail Part No.	Bulk Part No.	Figure Number	Description	Use with GC Wire Part No.
33-1404		13	2 Red/2 Black Posts, 3"L x 1"H, 2-1/2" Mounting Centers	14-218-2E_3

8 Position Pushbutton Terminal Board

Retail Part No.	Bulk Part No.	Figure Number	Description	Use with GC Wire Part No.
33-1408		14	4 Red/4 Black Posts, 2-1/2" x 5/8" x 1-3/16", 2-1/4" Mounting Centers	14-218-2E_3

AUDIO/VIDEO



ADAPTERS



Fig. 1



Fig. 2



Fig. 3



Fig. 4



Fig. 5



Fig. 6



Fig. 7



Fig. 8




Fig. 9



Fig. 10



Fig. 11

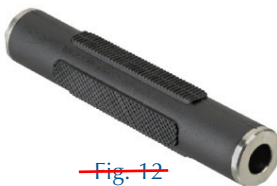

~~Fig. 12~~

Adapters

Retail Part No.	Bulk Part No.	Figure Number	Description
30-495	30-495-BU	1	3.5mm Mini Phone Plug to RCA Jack-all metal (Better)
30-472		2	1/4" Phone Plug to RCA Jack (Basic)
30-472-1		3	1/4" Mono Phone Plug to Mono 3.5mm Mini Phone Jack (Mono-Mono).(Basic)
30-478		4	2.5mm Subminiature Phone Plug to 3.5mm Phone Jack (Mono-Mono).(Basic)
30-1587		5	Mono 3.5mm Mini Phone Plug to Stereo 3.5mm Mini Phone Jack (Mono-Stereo).(Basic)
30-496		6	3.5mm Mini Phone Plug to 1/4" Phone Jack (Mono-Mono).(Basic)
30-1554		7	3.5mm Mini Phone Plug to 1/4" Stereo Phone Jack (Mono-Stereo).(Better)
30-1576		8	3.5mm Stereo Mini Phone Plug to 1/4" Stereo Phone Jack (Stereo-Stereo).(Basic)
30-1574		9	1/4" Stereo Phone Plug to 3.5mm Stereo Mini Phone Jack (Stereo-Stereo).(Basic)
30-1575		10	1/4" Stereo Phone Plug to 3.5mm Stereo Mini Phone Jack-Gold (Stereo-Stereo).(Best)
30-1571		11	3.5mm Stereo Mini Phone Jack to 3.5mm Stereo Mini Phone Jack (Stereo-Stereo).(Better)
30-1570		12	1/4" Mono Phone Jack to 1/4" Mono Phone Jack (Mono-Mono).(Basic)

For the latest information—www.gcelectronics.com

All quantities are single; BU's are packages of 10 Unless otherwise noted.