


Cylinder Type Polyacene Capacitors

PAS1020LA2R3475

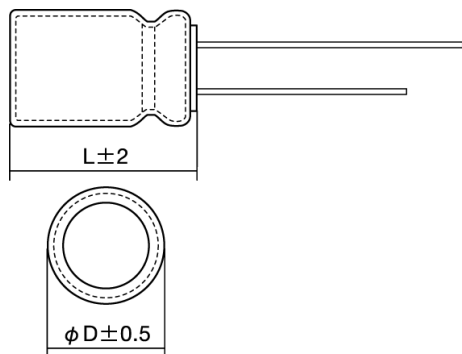

■ Features

- Item Summary
2.3V, 4.7F±20%, Less than 0.3Ω
- Lifecycle Stage
Phaseout
- Standard packaging quantity (minimum)
Bulk 100pcs

■ Products characteristics table

Temperature Range	-25 to +60°C
Maximum Usable Voltage	2.3V
Nominal Capacity	4.7F
Internal Resistance	0.3Ω
Initial Capacitance	4.7F±20%
Initial Internal Resistance	Less than 0.3Ω
RoHS Compliance	Yes
Soldering Method	Wave

2013.08.20

The data is reference only. Electrical characteristics vary depending on environment or measurement condition.
 TAIYO YUDEN reserves the right to make change to the Date at any time without notice.
 Before making final selection, please check product specification.