

09 12 240

Lineman's Pliers

American style



- improved version
- Now requires 50% less effort compared with conventional combination pliers due to an optimised transmission ratio
- solid construction for heaviest strain; universally applicable
- ergonomically optimised handle shape for firm contact to the hand and fatigue reducing operation
- particularly effective cross-hatched knurled gripping zone in the jaws - for strong gripping and pulling
- additional gripping zone below the joint for powerful leverage and pressing performance
- with cutting edges for soft and hard wire
- cutting edges additionally induction hardened, cutting edge hardness approx. 64 HRC
- Vanadium electric steel; forged, oil-hardened
- with fish tape puller in the joint gap
- with universal mandrel crimping point below the joint


Article No.	09 12 240
EAN	4003773071969
Pliers	black atramentized
Head	polished
Handles	with multi-component grips
medium hard wire Ø mm	4,6
hard wire Ø mm	3,0
Length mm	240
Net weight g	470



Long cutting edges for cutting flat cables



Gripping zone below the joint for powerful leverage

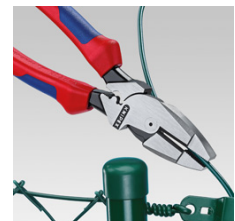

Cross-hatched, knurled gripping zone for firm gripping and pulling, e. g. for fence construction



09 11/12 240: fish tape puller in the joint gap



09 11/12 240: universal mandrel crimping area below the joint

technical change and errors excepted

