

power strips Housing made of impact-resistant plastic, halogen free!

with outlets in accordance with DIN VDE 0620-1 / 2005-04 - 16 A / 250 V ~

72 mm-wide strips

Cord 2.0 m, H05VV-F 3G1.5

with switch




without switch



60 mm-wide strips

Cord 2.0 m, H05VV-F 3G1.5

 with switch



without switch






72 mm strip width

90 °


rewireable

Execution and technical Data		Overall length	Order no. and Specify color necessarily	Computer Code
with 2-pole. Switches, illuminated	3X	283	5000 s / ws 3	05000.0S03.01.020
			5000 s / 3 sw	05000.0S03.02.020
	5X	403	5000 s / 3 si / sw	05000.0S03.09.020
			5000 s / sw 5	05000.0S05.02.020
			5000 S / 5 si / sw	05000.0S05.09.020
			5000 s / 6 ws	05000.0S06.01.020
6x	463	5000 s / 6 SW	05000.0S06.02.020	
		5000 s / 6 si / sw	05000.0S06.09.020	
		5000 s / ws 8	05000.0S08.01.020	
8 times	583	5000 s / 8 sw	05000.0S08.02.020	
		5000 s / 8 si / sw	05000.0S08.09.020	
		5000 s / ws 10	05000.0S10.01.020	
10X	703	5000 s / 10 sw	05000.0S10.02.020	
		5000 s / 10 si / sw	05000.0S10.09.020	
		5000 s / ws 12	05000.0S12.01.020	
12x	823	5000 s / 12 sw	05000.0S12.02.020	
		5000 s / 12 si / sw	05000.0S12.09.020	

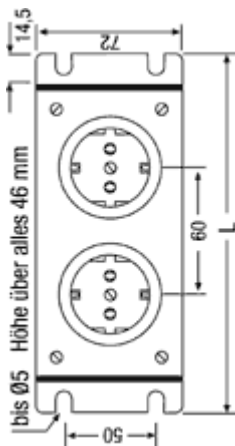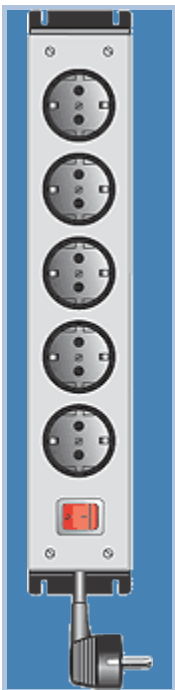


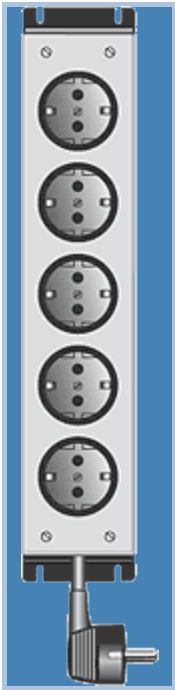


without switch	3X	251	5000/3 ws	05000.0003.01.020
			5000/3 SW	05000.0003.02.020
			5000/3 si / sw	05000.0003.09.020
	5X	371	5000/5 ws	05000.0005.01.020
			5000/5 SW	05000.0005.02.020
			5000/5 si / sw	05000.0005.09.020
	6x	431	5000/6 ws	05000.0006.01.020
			5000/6 SW	05000.0006.02.020
			5000/6 si / sw	05000.0006.09.020
	8 times	551	5000/8 ws	05000.0008.01.020
			5000/8 SW	05000.0008.02.020
			5000/8 si / sw	05000.0008.09.020
	10X	671	5000/10 ws	05000.0010.01.020
			5000/10 SW	05000.0010.02.020
			5000/10 si / sw	05000.0010.09.020
	12x	791	5000/12 ws	05000.0012.01.020
			5000/12 SW	05000.0012.02.020
			5000/12 si / sw	05000.0012.09.020

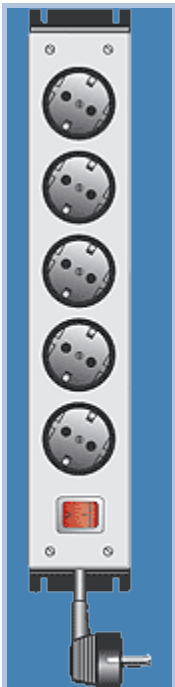


72 mm strip width		30 °		rewireable	
Execution and techn. Data		Overall length	Order no. and Specify color necessarily	Computer Code	
with 2-pole. Switches,	3X	283	5003 s / ws 3	05003.0S03.01.020	
illuminated			5003 s / 3 sw	05003.0S03.02.020	
			5003 s / 3 si / sw	05003.0S03.09.020	
	5X	403	5003 s / ws 5	05003.0S05.01.020	
			5003 s / sw 5	05003.0S05.02.020	
			5003 S / 5 si / sw	05003.0S05.09.020	
	6x	463	5003 s / 6 ws	05003.0S06.01.020	
			5003 s / 6 SW	05003.0S06.02.020	
			5003 s / 6 si / sw	05003.0S06.09.020	
	8 times	583	5003 s / ws 8	05003.0S08.01.020	
			5003 s / 8 sw	05003.0S08.02.020	

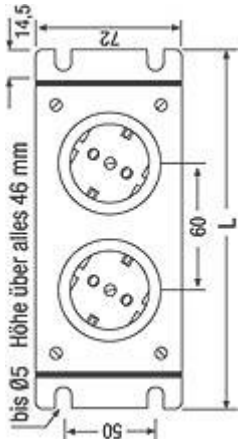

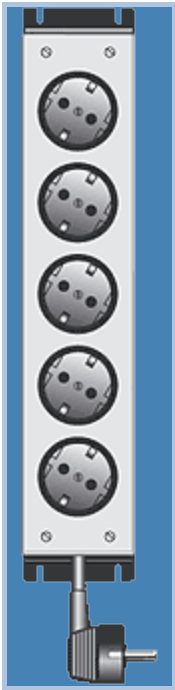

			5003 s / 8 si / sw	05003.0S08.09.020
	10X	703	5003 s / ws 10	05003.0S10.01.020
			5003 s / 10 sw	05003.0S10.02.020
			5003 s / 10 si / sw	05003.0S10.09.020
	12x	823	5003 s / ws 12	05003.0S12.01.020
			5003 s / 12 sw	05003.0S12.02.020
			5003 s / 12 si / sw	05003.0S12.09.020
without switch	3X	251	5003/3 ws	05003.0003.01.020
			5003/3 SW	05003.0003.02.020
			5003/3 si / sw	05003.0003.09.020
	5X	371	5003/5 ws	05003.0005.01.020
			5003/5 SW	05003.0005.02.020
			5003/5 si / sw	05003.0005.09.020
	6x	431	5003/6 ws	05003.0006.01.020
			5003/6 SW	05003.0006.02.020
			5003/6 si / sw	05003.0006.09.020
	8 times	551	5003/8 ws	05003.0008.01.020
			5003/8 SW	05003.0008.02.020
			5003/8 si / sw	05003.0008.09.020
	10X	671	5003/10 ws	05003.0010.01.020
			5003/10 SW	05003.0010.02.020
			5003/10 si / sw	05003.0010.09.020
	12x	791	5003/12 ws	05003.0012.01.020
			5003/12 SW	05003.0012.02.020
			5003/12 si / sw	05003.0012.09.020

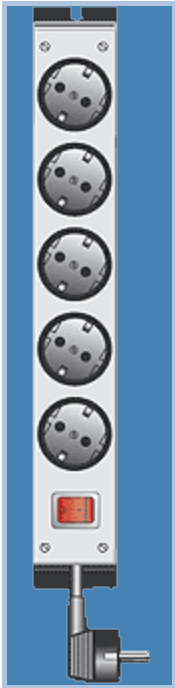

		60 mm strip width	30 °	rewireable	
with 2-pole. Switches, illuminated	3X	283	1003 s / ws 3	01003.0S03.01.020	
			1003 s / 3 sw	01003.0S03.02.020	
			1003 s / 3 si / sw	01003.0S03.09.020	
	5X	403	1003 s / ws 5	01003.0S05.01.020	
			1003 s / sw 5	01003.0S05.02.020	
			1003 S / 5 si / sw	01003.0S05.09.020	
	6x	463	1003 s / 6 ws	01003.0S06.01.020	
			1003 s / 6 SW	01003.0S06.02.020	
			1003 s / 6 si / sw	01003.0S06.09.020	
	8 times	583	1003 s / ws 8	01003.0S08.01.020	
			1003 s / 8 sw	01003.0S08.02.020	
			1003 s / 8 si / sw	01003.0S08.09.020	
	10X	703	1003 s / ws 10	01003.0S10.01.020	
			1003 s / 10 sw	01003.0S10.02.020	
			1003 s / 10 si / sw	01003.0S10.09.020	
without switch	3x	251	1003/3 ws	01003.0003.01.020	
			1003/3 SW	01003.0003.02.020	
			1003/3 si / sw	01003.0003.09.020	
	5x	371	1003/5 ws	01003.0005.01.020	
			1003/5 SW	01003.0005.02.020	
			1003/5 si / sw	01003.0005.09.020	
	6x	431	1003/6 ws	01003.0006.01.020	
			1003/6 SW	01003.0006.02.020	
			1003/6 si / sw	01003.0006.09.020	
	8 times	551	1003/8 ws	01003.0008.01.020	
			1003/8 SW	01003.0008.02.020	
			1003/8 si / sw	01003.0008.09.020	
	10X	671	1003/10 ws	01003.0010.01.020	
			1003/10 SW	01003.0010.02.020	
			1003/10 si / sw	01003.0010.09.020	

