

Loudspeakers

Background Music Loudspeakers

Indoor background music loudspeakers featuring ABS enclosures and sturdy metal grilles. Suitable for free standing or wall mounting via adjustable pivot fixing bracket, allowing horizontal or vertical installation. The trapezoidal design allows for the enclosures to be mounted neatly into corners, making them ideal for installation into bars, cafés, schools or domestic applications.




- 2-way low impedance loudspeakers
- Complete with adjustable mounting brackets
- Supplied in pairs
- Available in black or white
- Robust housing
- Polypropylene LF and Mylar HF



BGS 25

BGS 35

BGS 50

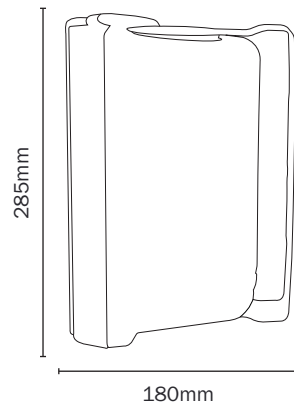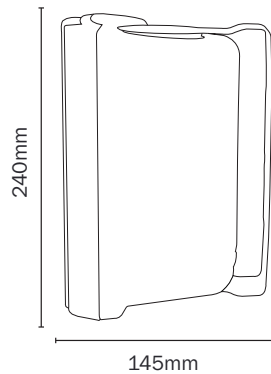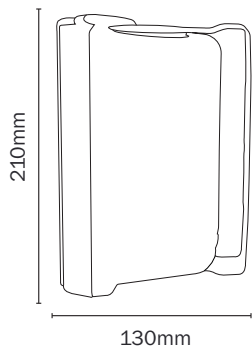

x2
SUPPLIED
IN PAIRS

Ω
LOW
IMPEDANCE

25W
rms

x2
SUPPLIED
IN PAIRS

Ω
LOW
IMPEDANCE

35W
rms

x2
SUPPLIED
IN PAIRS

Ω
LOW
IMPEDANCE

50W
rms

Specifications	BGS 25	BGS 35	BGS 50
Impedance:	8Ω	8Ω	8Ω
Power (RMS):	25W	35W	50W
Power (Max.):	50W	70W	100W
Sensitivity (1W/1m):	88dB	89dB	89dB
Maximum SPL (Rated W/1m):	95dB	98dB	98dB
Frequency response:	70Hz-18kHz	60Hz-18kHz	55Hz-20kHz
Drivers:	4" LF, 1" HF	5" LF, 1" HF	6.5" LF, 1" HF
Connections:	2 x binding terminals	2 x binding terminals	2 x binding terminals
Dimensions:	210 x 160 x 130mm	240 x 178 x 145mm	285 x 205 x 180mm
Weight:	1.5kg (each)	2.2kg (each)	3.2kg (each)
Order code:	CRSP23 (white), CRSP24 (black)	CRSP25 (white), CRSP26 (black)	CRSP27 (white), CRSP28 (black)