


## 5625////1121

Paguro gel connector junction box black, 4 cable entry 6.5-12mm cable with 3 pole terminal block

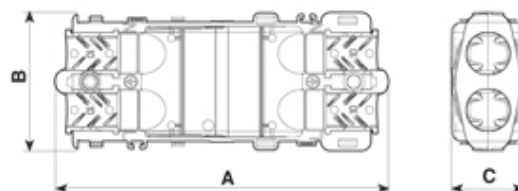

Dimensioni / Dimensions (mm)

A	B	C
105	44	24

Max volume interno disponibile ~ 14,26cm<sup>3</sup>

Max internal room available ~ 14.26cm<sup>3</sup>



### SPECIFICATION

Cable Entries	4
Number of Poles	3
Terminal Type	Screw - wp
Body Material	Nylon PA66-RV V0
Colour	Black
Max Conductor Size (Sq mm)	4
Max Current (A)	16
Max Voltage (V)	250
Minimum Temp Rating °C	-30
IP Rating	68
Max Temp Rating °C	130
Minimum Cable Diameter (mm)	6.5
Maximum Cable Diameter (mm)	12
Depth (mm)	24
Fixing System	Cable
Gel Material	Sealing bi-component syliconic gel
Length (mm)	95-105 depending on fitting of cable adapters
Width (mm)	44

### DISTRIBUTORS

