



CUSTOMER	CPC
PRODUCT NO.	CS287**Series
HENTEK NO.	HK-USB3.1BMC02-*Series

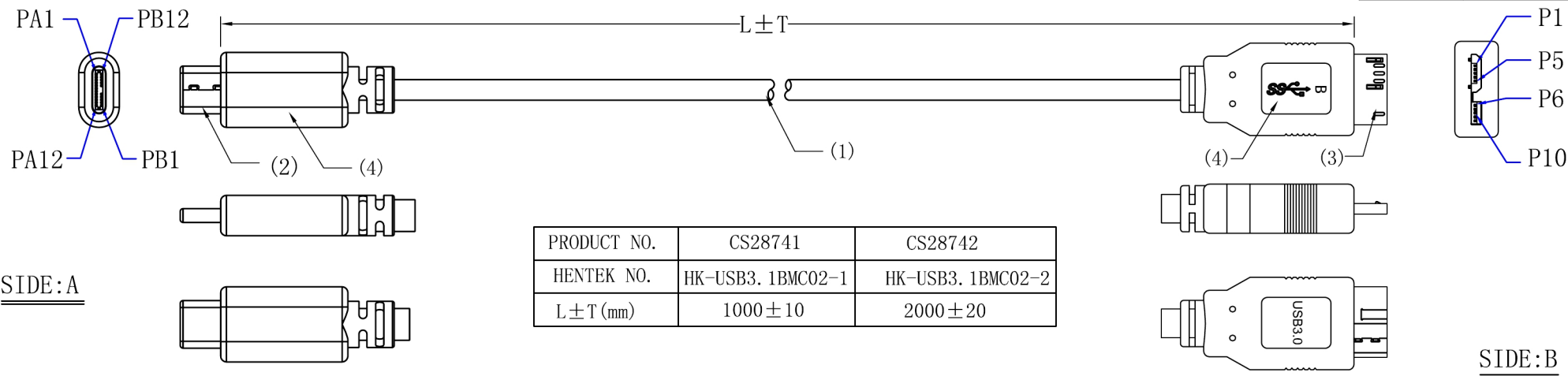

NOTE:

- Cable Spec: (30AWG*1P+DAM)*2+30AWG*1P+28AWG*2C
Jacket Material:PVC OD:4.6 ±0.2mm
Colour: Black
- Connector A: USB3.1 C MALE Solder type
Insulation:Black
Contacts:Gold Plated
Shell:Nickel Plated
- Connector B: USB3.1 MICRO B MALE Solder type
Insulation:Blue
Contacts:Gold Plated
Shell:Nickel Plated
- Over Mold Colour: PVC-Black
- Parameter Settings: CT-8681FA
 - Insulation Resistance:5MΩ (MIN.)
 - Conductive Resistance:2.0Ω (MAX.)
- 100% OPEN, SHORT&MISWIRE TEST
- PACKING:PEBAG PACKING.

SIDE:A		SIDE:B	
USB CM		Micro 3.1BM	
A4+B4+A9+B9	red	1	
A6	white	3	
A7	green	2	
A1+B1+A12+B12	black	5+8	
A2	blue	10	
A3	yellow	9	
A1+B1+A12+B12	drain	5+8	
B10	orange	6	
B11	purple	7	
A1+B1+A12+B12	drain	5+8	
Shell	braid	Shell	

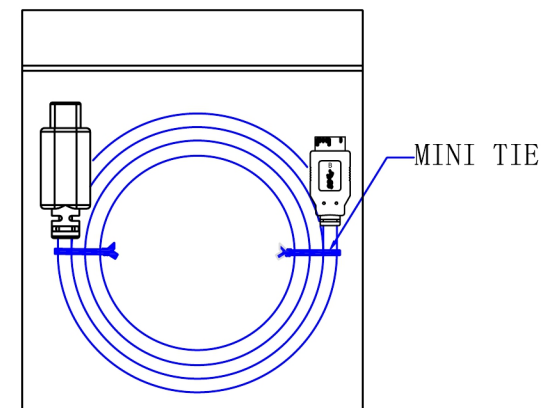

PIN OUT: (5)

PACKING: (7)

GENERAL TOLERANCES (UNLESS SPECIFIED)							
			UNIT:mm		REV:0/A		
			DRAWING	XIAODENG	2015/5/21	S. P. NO.	HT-6491
00	NEW	2015/5/21	CHECK			P. O. NO.	
REV	DESCRIPTION	DATE	APPROVE			SIZE	
						NAME	USB3.1 C MALE/MICRO B MALE
						DWG. NO.	
						PAGE	1/1